

# EMR 1030 V Earthmover Radial Tires

## PREMIUM RADIAL PNEUMATIC

The Trelleborg EMR range is designed to enhance productivity in critical construction applications, delivering both enhanced damage protection and durability.

The R1 tread pattern delivers control and perfect grip when it's needed the most, whether on soil, fields and mud.


The strong radial carcass and state of the art compound assure long life, while providing equal load distribution for a comfortable ride, maintaining low fuel consumption. EMR 1030 V is especially designed for loaders and dozer agriculture application.

### Main benefits

- Excellent self-cleaning properties
- Low vibration
- Cut resistant compound
- Robust carcass to support eventual retreading\*



### Application

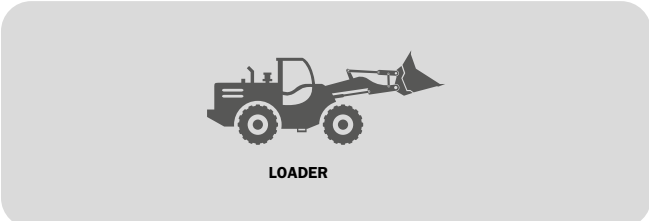

### Tire features

ALL-STEEL RADIAL CONSTRUCTION	REINFORCED CARCASS	MULTI SURFACE	EXCELLENT RIDE COMFORT

\*Carcass should be checked by a professional technician before retreading is permitted

# EMR 1030 V

PREMIUM RADIAL PNEUMATIC

Tire Size	Tread Pattern TRA	Rim Size (Permitted)	Tread Depth [mm]	Service description LI/SS Loader	Tire Load Capacity (kg) 10 (km/h)	Tire Pressure (bar)
<b>20.5 R 25</b>	L3	17.00/2.0-25 (17.00/1.7-25)	36	** 193 A2	11,500	5.75

\*\* - Index of tire strength



Follow us



Yokohama TWS S.p.A.  
Via Nazionale Tiburtina, 143 - 00019 Villa Adriana - Tivoli (RM), Italy  
Phone: +39 0774 3841 – info.tws@yokohama-tws.com  
www.trelleborg-tires.com

