




SAFETY CLAMP (Stainless steel 316)


V04/09/2016

TECHNICAL INFORMATION

- Material : stainless steel 316
- Included stainless steel bolt and nuts
- According to EN 1440-3

RELATED PRODUCTS

- All UTS couplings
- All couplings according to EN14420
- Autoblock nut 

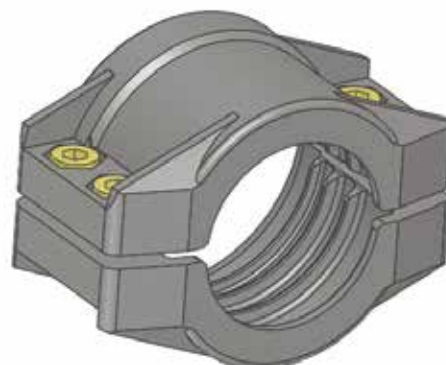

www.trelleborg.com/fluidhandling

Contact: robin.lallemand@trelleborg.com

SS 316

DN Hose	Ref	Size	Material	Min. OD Hose (mm)	Max. OD Hose (mm)	According to EN 14420-3	Stock
13	0117567	13 x 5	SS 316	22	24	yes	✓
19	0117568	19 x 6	SS316	30	33	yes	✓
25	0117569	25 x 6	SS 316	36	39	yes	✓
32	0117570	32 x 6	SS 316	43	46	yes	✓
38	0117571	38 x 6,5	SS 316	50	53	yes	✓
50-51	5108976	50 x 6	SS 316	60	64	-	✓
50-51	0117572	50 x 8	SS 316	63	67	yes	✓
63-65	5108975	63 x 6	SS 316	73	77	-	✓
63-65	0117573	63 x 8 - 65 X 7	SS 316	78	82	yes	✓
75-76	5103181	75 x 6,5	SS 316	86	90	-	✓
75-76	0117574	75 x 8	SS 316	89	93	yes	✓
100-102	0117575	100 x 8	SS 316	114	119	yes	✓
150-152	5105349	150 x 10	SS 316	167	173	yes	✓




SAFETY CLAMP (Aluminium)


V04/09/2016

TECHNICAL INFORMATION

- Material : aluminium
- Included zinc plated bolt and nuts
- According to EN 1440-3

RELATED PRODUCTS

- All UTS couplings
- All couplings according to EN14420
- Autoblock nut 

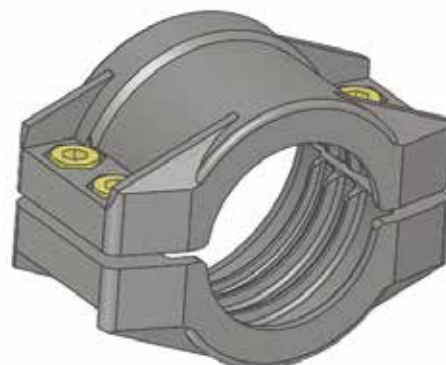

www.trelleborg.com/fluidhandling

Contact: robin.lallemand@trelleborg.com

SS 316

DN Hose	Ref	Size	Material	Min. OD Hose (mm)	Max. OD Hose (mm)	According to EN 14420-3	Stock
13	0117561	13 x 5	ALUMINIUM	22	24	yes	✓
19	0113472	19 x 6	ALUMINIUM	30	33	yes	✓
25	0732019	25 x 6	ALUMINIUM	36	39	yes	✓
25	0117562	25 x 8	ALUMINIUM	40	43	-	✓
32	0732020	32 x 6	ALUMINIUM	43	46	yes	✓
32	0117563	32 x 8	ALUMINIUM	46	50	-	✓
38	5108977	38 x 5	ALUMINIUM	47	44	-	✓
38	0731663	38 x 6,5	ALUMINIUM	50	53	yes	✓
38	0111749	38 x 8	ALUMINIUM	53	56	-	✓
38	0112011	38 x 10	ALUMINIUM	57	60	-	✓
40	0111985	40 x 7	ALUMINIUM	54	58	-	✓
50	5103175	50 x 2	ALUMINIUM	52	56	-	✓
50	5102436	50 x 5	ALUMINIUM	58	62	-	✓
50	5101018	50 x 6	ALUMINIUM	60	64	-	✓
50	0731664	50 x 8	ALUMINIUM	63	67	yes	✓
50	0111886	50 x 10	ALUMINIUM	68	72	-	✓

1/2



SAFETY CLAMP (Aluminium)

V04/09/2016

SS 316

DN Hose	Ref	Size	Material	Min. OD Hose (mm)	Max. OD Hose (mm)	According to EN 14420-3	Stock
65	5102976	63 x 6	ALUMINIUM	73	77	-	✓
65	0111750	63 x 8 - 65 x 7	ALUMINIUM	78	82	yes	✓
65	0111891	65 x 10	ALUMINIUM	83	87	-	✓
75	0731666	75 x 8	ALUMINIUM	89	93	yes	✓
75	0732012	75 x 10	ALUMINIUM	93	97	-	✓
75	0117564	75 x 12	ALUMINIUM	97	101	-	✓
80	0111751	80 x 8	ALUMINIUM	95	98	-	✓
80	0111895	80 x 10	ALUMINIUM	98	102	-	✓
90	5105883	90 x 5,5	ALUMINIUM	99	103	-	✓
100	0731667	100 x 8	ALUMINIUM	114	119	yes	✓
100	0111899	100 x 10	ALUMINIUM	118	122	-	✓
100	0111249	100 x 12	ALUMINIUM	122	126	-	✓
100	0111582	100 x 14	ALUMINIUM	126	130	-	✓
100	0113652	100 x 16	ALUMINIUM	130	134	-	✓
110	5105884	110 x 6,5	ALUMINIUM	121	125	-	✓
125	0111752	125 x 10	ALUMINIUM	143	147	-	✓
125	0117565	125 x 15	ALUMINIUM	153	157	-	✓
150	0111753	150 x 10	ALUMINIUM	167	173	yes	✓
150	0117566	150 x 13	ALUMINIUM	174	178	-	✓
150	0111754	150 x 15	ALUMINIUM	178	182	-	✓
200	0111756	200 x 12	ALUMINIUM	222	229	yes	✓

2/2

