



KC
King combination nipple

KC

King combination nipple



MATERIAL MATIÈRE MATERIAL


- AL** = Aluminium
- ST** = Steel *Acier Acero*
- SS** = Stainless steel *Inox*

SIZE DIMENSIONS DIMENSIONES

From DN 1" to DN 6"

THREAD FILETAGE ROSCA

BSPT ISO 7/1

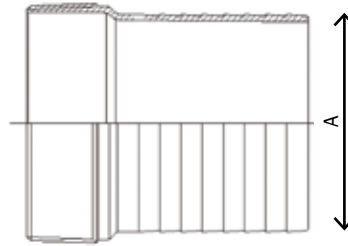

| DN | A |
|-------|-----|
| 1" | 25 |
| 1"1/4 | 32 |
| 1"1/2 | 38 |
| 2" | 51 |
| 2"1/2 | 64 |
| 3" | 77 |
| 4" | 102 |
| 5" | 128 |
| 6" | 152 |

AL = Aluminium BR = Brass Laiton Latón ST = Steel Acier Acero SS = Stainless steel Inox PP = Polypropylene

Trelleborg Fittings 2015

| | | ID coupling Diam. raccord Diam. racor | ID shank Diam. douille Diam. espiga | Ref. | Notes |
|---|--------|---|---|-----------|-------|
|  <p>Male thread. With collar. Fileté mâle. Avec collerette. <i>Rosca macho. Con cuello.</i></p> | AL | 2" | 50 | 510 20 73 | |
| | | 2"1/2 | 65 | 510 20 74 | |
| | | 3" | 75 | 510 20 75 | |
| | | 4" | 100 | 510 20 76 | |
|  <p>Male thread. Fileté mâle. <i>Rosca macho.</i></p> | ST | 1" | 25 | 091 44 57 | |
| | | 1"1/4 | 32 | 091 44 65 | |
| | | 1"1/2 | 38 | 091 44 73 | |
| | | 2" | 50 | 091 44 80 | |
| | | 2"1/2 | 65 | 091 44 99 | |
| | | 3" | 75 | 091 45 07 | |
| | | 4" | 100 | 091 45 15 | |
| | | 5" | 125 | 091 45 23 | |
|  <p>For welding BW. A souder BW. <i>Para soldar BW.</i></p> | ST | 1" | 33,7 | 510 51 04 | |
| | | 1"1/4 | 42,2 | 510 51 05 | |
| | | 1"1/2 | 48,3 | 510 51 06 | |
| | | 2" | 60,3 | 510 51 07 | |
| | | 2"1/2 | 76,1 | 510 51 08 | |
| | | 3" | 88,9 | 510 51 09 | |
| | | 4" | 114,3 | 510 51 10 | |
| | | 5" | 139,7 | 510 51 11 | |
|  <p>Male thread. Fileté mâle. <i>Rosca macho.</i></p> | SS 316 | 1" | 25 | 510 51 13 | |
| | | 1"1/4 | 32 | 510 51 14 | |
| | | 1"1/2 | 40 | 510 51 15 | |
| | | 2" | 50 | 510 51 16 | |
| | | 2"1/2 | 65 | 510 51 17 | |
| | | 3" | 75 | 510 51 18 | |
| | | 4" | 100 | 510 51 19 | |
| | | 5" | 125 | 510 51 20 | |
|  <p>For welding BW. A souder BW. <i>Para soldar BW.</i></p> | SS 316 | 1" | 33,7 | 510 51 22 | |
| | | 1"1/4 | 42,2 | 510 51 23 | |
| | | 1"1/2 | 48,3 | 510 51 24 | |
| | | 2" | 60,3 | 510 51 25 | |
| | | 2"1/2 | 76,1 | 510 51 26 | |
| | | 3" | 88,9 | 510 51 27 | |
| | | 4" | 114,3 | 510 51 28 | |
| | | 5" | 139,7 | 510 51 29 | |
| | | 6" | 168,3 | 510 51 30 | |