



Rollin[®] Contrast Red


Key performance

- Excellent half tone reproduction
- Implements all benefits of the **Dynatech System:**
 - Better vibration absorption
 - Less gears streaking marks
 - Higher paper smash resistance
 - Blanket consistency
 - Excellent reboundability

MAIN APPLICATION

Commercial Sheetfed

Rollin Contrast Red is available in 3-ply, 1,95 mm tickness

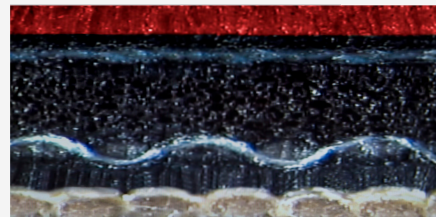

Rollin Contrast Red



The product at a glance

INK COMPATIBILITY	Hybrid
PRINTING SURFACE COLOUR	Red
THICKNESS (mm)	1,95
AVERAGE LOAD VALUE N/cm2 @ 0,23 mm Indentation	250
SURFACE ROUGHNESS (Ra micron)	0,6
ELONGATION (%)	<0,9
TENSILE STRENGTHS (N/mm)	>60
WATER & SOLVENT PROTECTION	Yes
NEW TECHNOLOGY	Dynatech System
ADDITIONAL INFORMATION	
CONSTRUCTION	Very special compressible layers

**FOR ANY FURTHER DETAILS AND FOR A QUOTATION
PLEASE REFER TO YOUR SALES MANAGER
OR EMAIL US AT: printingsm@trelleborg.com**