

Printec Intaglio


Key performance

- Blanket used as impression cylinder with extremely high stability and mechanical resistance
- Surface able to allow a proper foil release and excellent ink transfer even at low pressure
- High temperature resistance over 100 °C

Printec Intaglio is available in 1-ply, 0,50 mm thickness

MAIN APPLICATION

Security Printing

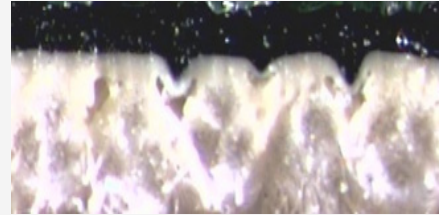

Printec Intaglio



The product at a glance

INK COMPATIBILITY	Conventional
THICKNESS (mm)	0,50 +0,04/-0,03
PRINTING SURFACE COLOUR	Black
COMPRESSIBILITY	Not compressible
TABER ABRASION (WEIGHT 500g, WHEEL H22, 500 CYCLES)	≤7%
ELONGATION (% , WARP/WEFT)	≤8/≤20
TENSILE STRENGTHS (N/5 cm, WARP/WEFT)	≥1400/≥250
ADDITIONAL INFORMATION	
APPLICATIONS	Printing of banknotes, checks, passports, visa

**FOR ANY FURTHER DETAILS AND FOR A QUOTATION
PLEASE REFER TO YOUR SALES MANAGER
OR EMAIL US AT: printingsm@trelleborg.com**