

vulcan Intaglio


Key performance

- Blanket used as impression cylinder with extremely high stability and mechanical resistance
- Surface able to allow a proper foil release and excellent ink transfer even at low pressure
- High temperature resistance over 100 °C

Vulcan Intaglio is available in 1-ply, 0,50 mm thickness

MAIN APPLICATION

Security Printing

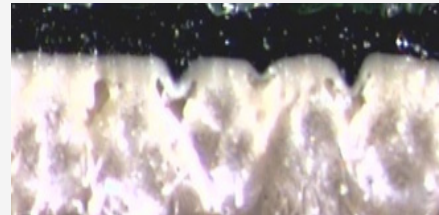

Vulcan Intaglio



The product at a glance

| | |
|--|--|
| INK COMPATIBILITY | Conventional |
| THICKNESS (mm) | 0,50 +0,04/-0,03 |
| PRINTING SURFACE COLOUR | Black |
| COMPRESSIBILITY | Not compressible |
| TABER ABRASION (WEIGHT 500g, WHEEL H22, 500 CYCLES) | ≤7% |
| ELONGATION (% , WARP/WEFT) | ≤8/≤20 |
| TENSILE STRENGTHS (N/5 cm, WARP/WEFT) | ≥1400/≥250 |
| ADDITIONAL INFORMATION | |
| APPLICATIONS | Printing of banknotes, checks, passports, visa |

**FOR ANY FURTHER DETAILS AND FOR A QUOTATION
PLEASE REFER TO YOUR SALES MANAGER
OR EMAIL US AT: printingsm@trelleborg.com**