

## ● Cushyfloat™ Special






### Features

The design incorporates bump and rebound control features, which limit excessive movements under shock loading. Top metal cover gives protection against oil contamination. Protective finish resists corrosion attack.

Metalastik® Cushyfloat™ special is designed for rough off highway environment. Used on engines for small ADT and Excavator etc.

17-2153 Typical Static Vertical Stiffness

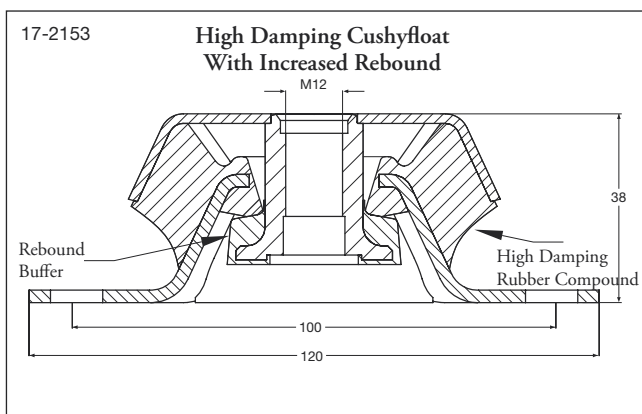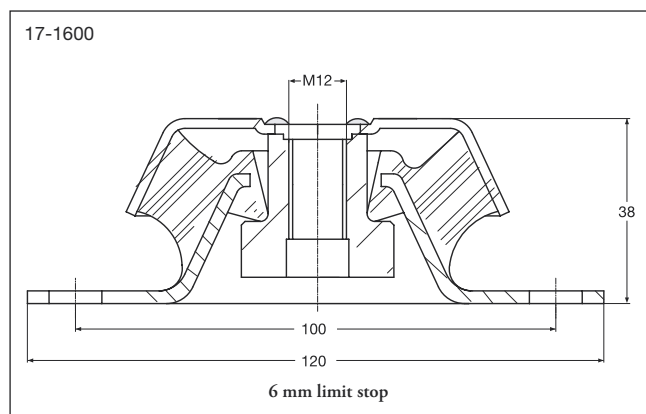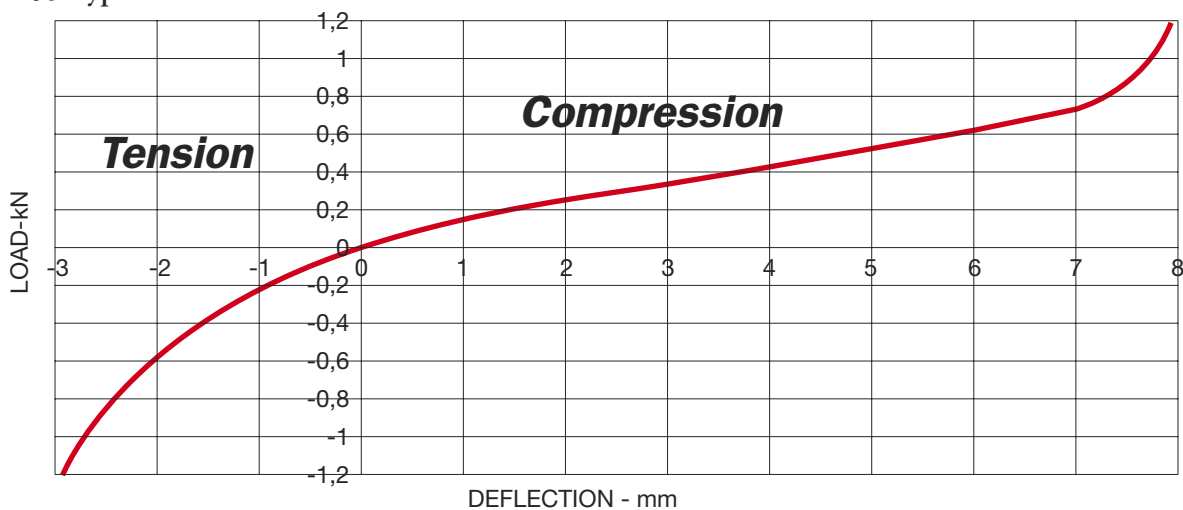

### Cushyfloat special

Type	Part no.	Max. Bolt Torque Nm	Max. Load kg	Comments
17-1600-11	10-00738-01	25	35	medium damping
17-1600-25	10-00933-01	25	35	High damping
17-1600-26	10-00934-01	25	55	High damping
17-1600-27	10-02624-01	25	35	High damping - vertical downwards limit stop
17-2153-00	10-00987-01	25	35	High damping - moulded rebound buffer
17-2153-01	10-01045-01	25	55	High damping - moulded rebound buffer