

Trelleborg Sealing Profiles

Solutions that Seal, Damp and Protect

Damper gasket

damper valve gasket

Damper valve gasket

This gasket is made from high quality black EPDM rubber.

A dual component gasket with antifriction treatment.


Solid rubber in the fitting part combined with cellular rubber that handles the sealing function and also seals effectively on uneven surfaces.

Our unique anti friction treatment reduces the torque needed.

Easy fit is already thought of in the design.

Manufactured with a technique that prevents hardened joints that could cause leakage.

Product no.	Pipe Ø mm	Length mm	Tolerance on length	Pallet qty.	Box qty.
71304518	100	270	± 3,2	10400	1300
71304501	120	325	± 3,2	9200	1150
71304519	125	340	± 3,2	8800	1100
71304502	140	370	± 3,2	8000	1000
71304503	150	400	± 3,2	7600	950
71304504	160	425	± 4,0	7200	900
71304505	180	485	± 4,0	6400	800
71304506	200	540	± 4,0	5600	700
71304507	220	615	± 4,0	4800	600
71304508	250	690	± 5,0	4400	550
71304509	280	780	± 5,0	4000	500
71305310	300	835	± 5,0	3600	450
71305311	315	880	± 5,0	3600	450
71305312	350	995	± 5,0	2800	350
71304520	355	1010	± 6,3	2800	350
71305313	400	1125	± 6,3	2800	350
71305314	450	1275	± 6,3	2400	300
71305315	500	1420	± 6,3	4000	250
71305316	560	1595	± 6,3	4000	250
71305317	630	1795	± 10,0	1600	200

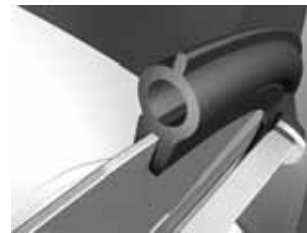


Ventiseal F-type

F-shaped ventilation gasket

Ventiseal F-type

A gasket with two lips that is made from high quality solid EPDM. This gasket is also suitable for automated fitting. This F-shape gasket protects the installer from sharp edges and also aids the automated process.

The gasket is also produced with anti-friction treatment for ease installation.

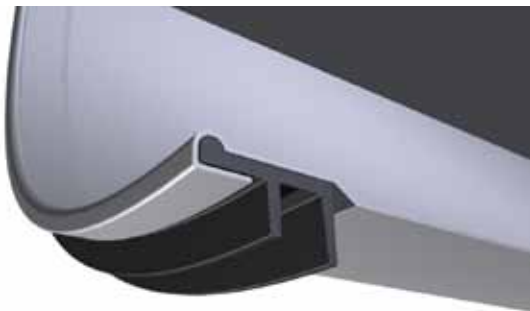

Product no.	Pipe Ø mm	Length mm	Tolerance on length	Pack.	Pack. qty.
413124304	80	231	± 2,0	Box	2000
413124301	100	289	± 2,5	Box	1800
413124303	125	352	± 2,5	Box	1500
413124305	140	395	± 3,2	Box	1400
413214306	150	428	± 3,2	Box	1300
413124307	160	462	± 4,0	Box	1200
413124308	180	523	± 4,0	Box	1000
413123504	200	578	± 4,0	Box	750
413123506	250	707	± 5,0	Box	600
413123507	280	791	± 5,0	Box	500
413123508	315	890	± 6,3	Box	600
413123509	355	1030	± 6,3	Box	500
413123510	400	1130	± 6,3	Box	500
413131708	450	1295	± 6,3	Box	500
413131709	500	1440	± 6,3	Box	500
413131718	630	1793	± 6,3	Box	250


Ventiseal T-type

ventilation gasket

Ventiseal T-type

This gasket made from black EPDM rubber is spliced to form rings. A gasket for sealing the joint of ventilation tubes.

A dual component gasket with antifriction treatment.

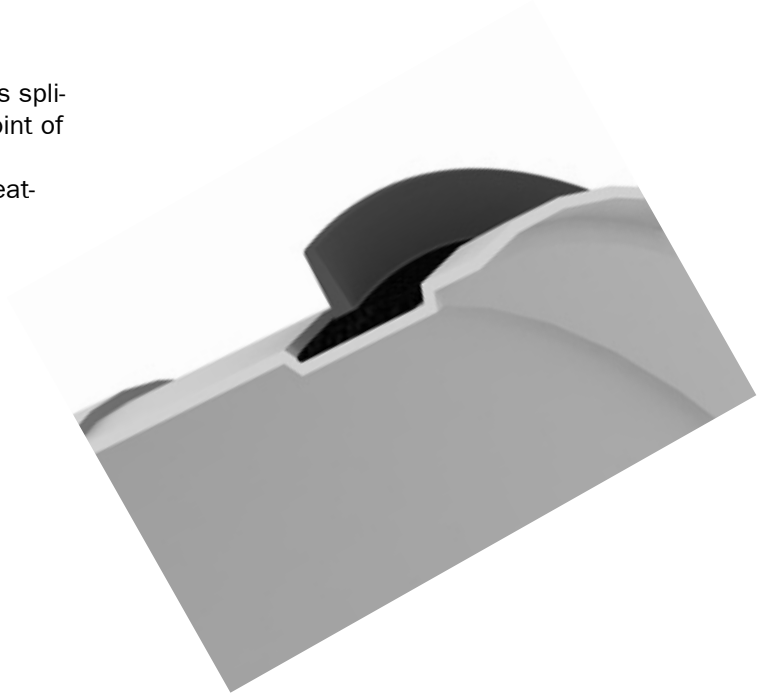

Dual component

Product no.	Pipe Ø mm	Length mm	Tolerance on length	Pack.	Pack. qty.
713170701	80	206	± 2,5	Box	1000
713170702	100	263	± 3,2	Box	1000
713170703	125	334	± 3,2	Box	1000
713170704	160	432	± 4,0	Box	800
713170705	200	515	± 4,0	Box	750
713170706	250	649	± 5,0	Box	750
713170707	315	822	± 5,0	Box	500
713170708	400	1041	± 6,3	Box	500
713170709	500	1295	± 6,3	Box	250

Ventiseal L-type

L-shaped ventilation gasket

Ventiseal L-type

This L-shaped gasket is made from high quality EPDM. The gasket is built up in modules which make it possible to adapt the hardness according specific needs.

This gasket is also suitable for automatized fitting. The absence of sharp edges is a good thing both in the automatized production as well as for the installer.

The gasket could be dyed in a number of colours and the surface is suitable for printing. A dual component gasket with antifriction treatment.



Dual component

Product no.	Pipe Ø mm	Length mm	Tolerance on length	Pack.	Pack. qty.
713169702	100	289	± 2,5	Box	1 000
713169703	125	361	± 3,2	Box	900
713169704	160	462	± 3,2	Box	800
713169705	200	578	± 4,0	Box	750
713169706	250	723	± 5,0	Box	750
713169707	315	910	± 5,0	Box	500

Ventiseal G-type

ventilation gasket

Ventiseal G-type

This gasket is made from high quality two-component EPDM, solid and cellular. Cellular rubber can cover a wider range of tolerances. The gasket is built up in modules which makes it possible to adapt the hardness according to specific needs. This gasket is also suitable for automated fitting. The absence of sharp edges is a good thing both in automated production as well as for the installer.


The gasket could be dyed in a number of colours and the surface is suitable for printing. A dual component gasket with antifriction treatment.



Dual component



Product no.	Pipe Ø mm	Length mm	Tolerance on length	Pack.	Pack. qty.
713173621	100	281	± 2,5	Box	1000
713173622	130	374	± 3,2	Box	1000
713173721	150	433	± 3,2	Box	1000
713173722	180	506	± 4,0	Box	800
713173723	200	551	± 4,0	Box	750
713173724	230	654	± 5,0	Box	750
713173821	250	719	± 5,0	Box	500
713173822	300	856	± 6,3	Box	500
713173823	350	984	± 6,3	Box	250
713173824	400	1142	± 6,3	Box	400
713173825	450	1280	± 6,3	Box	450
713173826	500	1427	± 6,3	Box	500
713173827	550	1575	± 6,3	Box	550
713173828	600	1722	± 6,3	Box	600

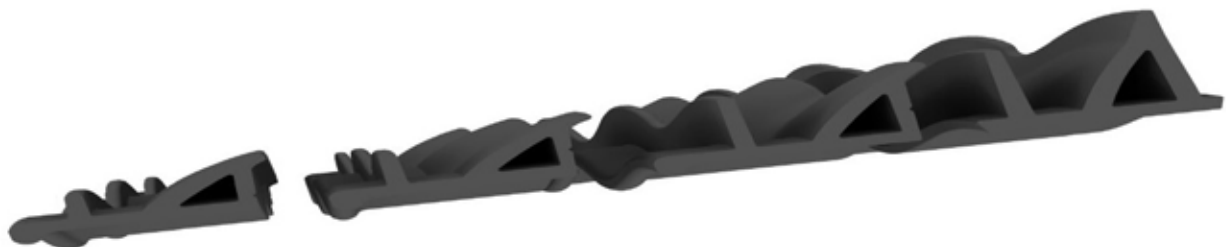

seal damp protect



Find your contact at

www.trelleborg.com/sealingprofiles