


# BLOC-END®

## CONSTRUCTION & ENVIRONMENT

For material handling hoses

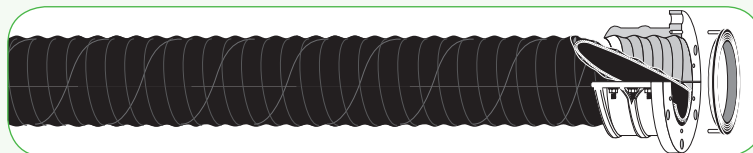

### Applications

Connection of the PERFORMER hoses: PERFORMER GL AD10H, PERFORMER GL AD10P, PERFORMER GL AD10T.

### Advantages

- Hoses can be cut to length on site or at manufacture to suit the specific installation requirements.
- Easy to cut: no special equipment is needed as the coupling face acts as a cutting guide.
- The flange can be adjusted easily for fitting and will not deform in service.
- Quick and easy to replace.
- The couplings can be removed from a damaged hose and reused on replacement.
- A lightweight connection system.

### Technical description

PERFORMER hoses fitted with BLOC-END® couplings are suitable for:  
 ID ≤ 150 mm: WP 10 bar,  
 ID > 150 mm: WP 5 bar.

### Complementary information

Coupling protection with Teflon upon request.

## BLOC-END®

16/04/2010

	<p>Complete BLOC-END® coupling. Including half shells, gasket and bolts, nuts, washers.</p> <p>PN 10      PN 20 (ASA 150)</p>		<p>Spare part-kit. Containing 2 half shells only, without gaskets and bolts.</p> <p>PN 10      PN 20 (ASA 150)</p>		<p>Spare part-kit. Containing 2 gaskets only.</p> <p>PN 10 and PN 20 (ASA 150)</p>	<p>Bolt, including nut and washer.</p>	
ID mm	Article number	Article number	Article number	Article number	Article number	Bolts quantity	Article number per piece
40	0117042	Consult us	0116890	Consult us	0116966	4	0111322
50	0117043	0117155	0116891	0116892	0116967	4	0111322
65	0117044	0117156	0116893	0116894	0116968	4	0111322
80	0117045	0117157	0116895	0116896	0116969	4	0111322
100	0117046	0117158	0116897	0116898	0116970	4	0111322
125	0117047	0117159	0116899	0116900	0116971	4	0111322
150	0117048	0117048	0116901	0116901	0116972	4	0111322
200	0117049	0117160	0116902	0116903	0116973	6	0111322
250	0118093	0118094	0118089	0118090	0118087	6	0111322
300	0118095	0118096	0118091	0118092	0118088	6	0111322
350	5101097	Consult us	5100847	Consult us	5100848	6	5102957
400	5102956	Consult us	5102955	Consult us	5102953	6	5102957

References in green = stock.

References in black, minimum of order = 2 pieces.

