

# TRELLVAC Handler MD



CONSTRUCTION & ENVIRONMENT  
Evacuation and material handling hoses

## Applications

Medium duty working hose on vacuum cleaning trucks for use at the work site.

## Advantages

- n Light and flexible with good wear resistance.
- n Specially designed for light materials transport and very easy handling.

## Technical description

Inner tube: wear resistant NR, black, smooth.

Reinforcement: synthetic textile, woven fabric with embedded steel helix.


Cover: wear and weather resistant SBR, black, corrugated.

Temperature range: - 30 °C to + 90 °C.

Electrical properties: non conductive tube.

## Complementary information

OD measured on top of corrugation.

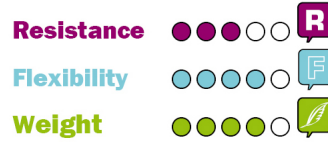

# TRELLVAC Handler MD

21/11/2011

ID mm		OD mm		Max. vacuum bar	Bending radius mm	Weight kg/m	Length m	Article number	Stock (n) or min. order m
51	+ 1.5/- 1.5	63.0	± 1.5	0.9	300	1.3	12	5501133	12
76	+ 1.5/- 1.5	91.0	± 1.5	0.9	350	2.0	12	1776690	n
102	+ 1.5/- 1.5	118.0	± 1.5	0.9	400	2.9	12	1776700	n
127	+ 1.5/- 1.5	144.0	± 1.5	0.9	500	3.9	12	1973590	n
152	+ 1.5/- 1.5	167.0	± 1.5	0.9	600	4.5	12	1776710	n
178	+ 1.5/- 1.5	195.0	± 1.5	0.9	700	5.2	12	2303130	12
204	+ 1.5/- 1.5	224.0	± 1.5	0.9	800	7.0	12	1776720	12

## Branding

