



HPS Solidflex
Traction

Brawler HPS Telehandler

PREMIUM SOLID

Brawler HPS (High Performance Solid) Telehandler tires are the best choice to perform in demanding environments.


The PROSOFT line is designed to deliver an excellent ride, prolonging operating time for equipment which results in reduced equipment and operator fatigue.

The wide, flat tread design provides excellent stability and extended operating hours.

Main Benefits

- Excellent ride comfort
- Durable cut-resistant rubber compound eliminates downtime caused by flats and sidewall cuts
- Press on to flat-based wheels
- Deep lug tread design offers three times more wear than a pneumatic tire
- Excellent traction

Application

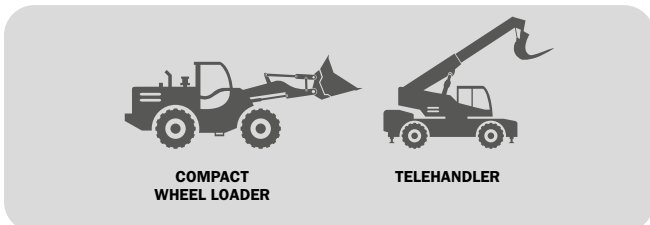

Tire Features



Brawler HPS Telehandler

PREMIUM SOLID


HPS SOLIDFLEX TRACTION

Tire Size	Alternative Metric Size	Rim Size	Overall Diameter [mm]	Section Width [mm]	Tread Depth [mm]	Load Capacity 10 km/h [kg]
43x15-24	405/70-20	10.0-24	1,090	380	82	5,600
47x17-24	405/70-24	10.0-24	1,190	430	100	6,300
13.00-24		8.5-24	1,295	330	102	5,935
14.00-24	385/95-24	8.5-24	1,345	356	112	6,705


Comparing Telehandler Prosoft vs Regular

Deflection - Index %	+12%
Footprint - Index %	+6%

DEFLECTION

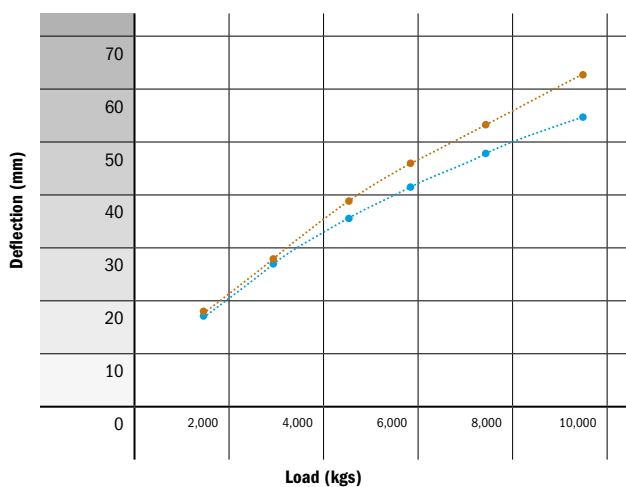

FOOTPRINT

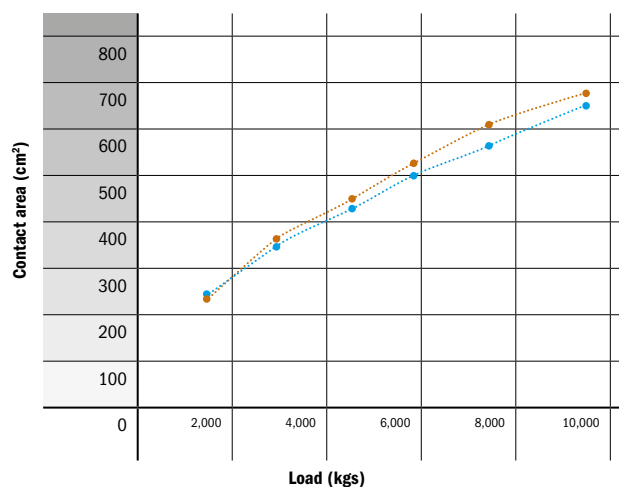

- HPS SF Traction Prosoft
- HPS SF Traction Regular

- HPS SF Traction Prosoft
- HPS SF Traction Regular



Yokohama TWS S.p.A.
 Via Nazionale Tiburtina, 143 - 00019 Villa Adriana - Tivoli (RM), Italy
 Phone: +39 0774 3841 – info.tws@yokohama-tws.com
 www.trelleborg-tires.com

Follow us

