



TRELLEBORG


# Trelleborg



# The perfect choice for a low intensity application

The new Trelleborg XP700 tire has been designed to perfectly match the needs of low intensity material handling operations.

Providing adequate load capacity and good steering ability, it offers the proper reliability, whilst maintaining cost control.

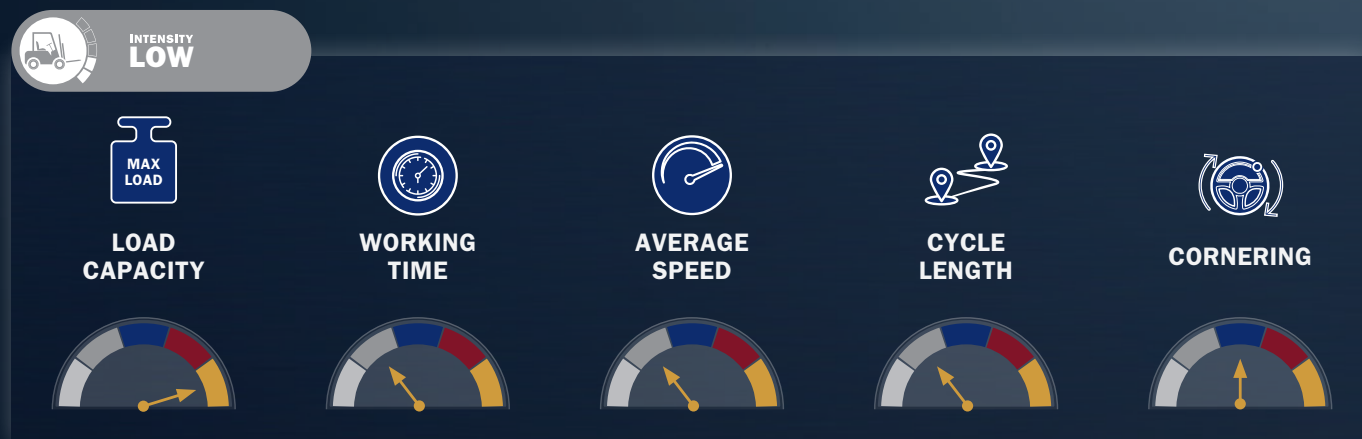

- 1 Compact lateral block design to minimize vibrations
- 2 Very deep lugs to enhance traction
- 3 Protruding rim protector in order to minimize damage to the wheels



# XP700

Size	Alternative Size	Rim	Pattern	LOC + STD	Product Dimensions [mm]		Load capacity [kg]		
					Overall Diameter	Section Width	Static	Counterbalanced lift trucks up to 25 km/h	
								Load Wheel	Steering Wheel
15x4½-8	125/75-8	3.00D-8	Traction	●	374	109	1.210	1.040	800
5.00-8		3.00D-8	Traction	●	451	115	1.650	1.415	1.090
16x6-8	150/75-8	4.33R-8	Traction	●	409	143	1.740	1.495	1.150
18x7-8	180/70-8	4.33R-8	Traction	●	447	147	2.490	2.145	1.650
140/55-9	15x5.5-9	4.00E-09	Traction	●	373	130	1.360	1.170	900
6.00-9		4.00E-09	Traction	●	521	128	2.190	1.885	1.450
21x8-9	200/75-9	6.00E-09	Traction	●	514	180	3.200	2.755	2.120
6.50-10		5.00F-10	Traction	●	569	154	2.720	2.340	1.800
200/50-10		6.50F-10	Traction	●	451	187	2.870	2.470	1.900
23x9-10	225/75-10	6.50F-10	Traction	●	574	188	4.000	3.445	2.650
7.00-12		5.00S-12	Traction	●	648	163	3.380	2.920	2.240
23x10-12	250/60-12	8.00G-12	Traction	●	576	231	4.380	3.770	2.900
27x10-12	250/75-12	8.00G-12	Traction	●	670	227	4.530	3.900	3.000
7.00-15	29x8-15	5.5-15	Traction	●	717	177	4.115	3.545	2.725
8.25-15		6.5-15	Traction	●	806	194	5.510	4.750	3.650
28x9-15	225/75-15 (8.15-15)	7.0-15	Traction	●	683	203	4.530	3.900	3.000
250-15	250/70-15	7.0-15	Traction	●	710	206	5.510	4.745	3.650
250-15	250/70-15	7.5-15	Traction	●	710	235	5.510	4.745	3.650
300-15	315/70-15	8.0-15	Traction	●	808	244	6.795	5.850	4.500
355/65-15	32x12½-15 (350-15)	9.75-15	Traction	●	813	269	9.060	7.800	6.000





Discover our website

Follow us

