




America

# CERTIFICATE

No. U8V 109000 0003 Rev. 00

**Holder of Certificate:** Trelleborg Industrial Products  
**Finland Oy**  
Kikkerlöntie 72  
38300 Sastamala  
FINLAND

**Certification Mark:**

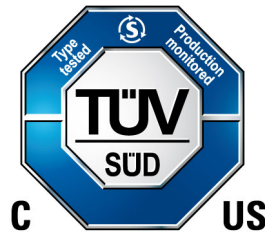

**Product:** Enclosures

This product was voluntarily tested to the relevant safety requirements referenced on this certificate. It can be marked with the certification mark above. The mark must not be altered in any way. This product certification system operated by TÜV SÜD America Inc. most closely resembles system 3 as defined in ISO/IEC 17067. Certification is based on the TÜV SÜD "Testing and Certification Regulations". TÜV SÜD America Inc. is an OSHA recognized NRTL and a Standards Council of Canada accredited Certification body.

**Test report no.:** 713201862

**Date,** 2021-02-19

( Susanne Dormann )



America

# CERTIFICATE

No. U8V 109000 0003 Rev. 00

**Model(s):**

- MH10 F 12-1
- MH16 F 17-1
- MH24 F 17-2
- MH24 F 22-1
- MH24 F 17-3
- MH24 F 27-1
- MH24 F 30-1
- MH24 F 30-2
- MH24 F 23-1
- MH24 F 20-1
- MH24 F 42-1
- MH24 F 125-1
- MH24 F 30-3
- MH24 F 23-3
- MH24 F 31-1
- MH24 F 19-1

**Tested according to:**

- UL 50:2015
- UL 50E:2015
- CSA-C22.2 No. 94.1:2015/R:2020-10
- CSA-C22.2 No. 94.2:2020

**Parameters:**

- Ambiente Temperature: 40°C
- IP66
- NEMA Type 1, 2, 12

**When installing all requirements of mentioned test specification(s) must be fulfilled.**