

# High quality support syntactic floats

## Njord Trimsyn & Njord Trimlok

Njord Trimsyn syntactic floats are manufactured using high performance syntactic foam and are floats which offer additional buoyancy in all marine applications, such as umbilical cable support, ROV trim buoyancy or as simple installation aids.

To streamline the attachment of Njord Trimsyn floats, we developed the Njord Trimlok umbilical clamp. Molded in a marine grade polyurethane elastomer, the clamp is sized to fit around a cable or umbilical, providing positive grip without damaging the structure of the umbilical.

### Features & benefits

Njord Trimsyn syntactic floats and Njord Trimlok attachments offer excellent features and benefits and are safe, efficient and easy to use. As the product is off the shelf stock orders and delivery are quick and easy.

### Positive connection

A large eyebolt swivel assembly allows the Njord Trimlok to remain attached to the float by means of a karabiner and pendant wire.


### Easy installation

Njord Trimlok eyebolt is suitably sized for operation by cold or gloved hands.



## NJORD TRIMSYN SPECIFICATIONS

Type-depth	Buoyancy	Weight in air	Height (h)	Diameter (D)	Bore (b)
MTS-000	13.50 kg	3.90 kg	340 mm	300 mm	18 mm
MTS-1000	7.40 kg	10.20 kg	340 mm	300 mm	18 mm
MTS-2000	7.10 kg	10.80 kg	340 mm	300 mm	18 mm
MTS-3000	5.40 kg	12.20 kg	340 mm	300 mm	18 mm
MTS-4000	5.30 kg	12.40 kg	340 mm	300 mm	18 mm
MTS-6000	5.00 kg	12.70 kg	340 mm	300 mm	18 mm
<hr/>					
TS1-000	21.70 kg	5.60 kg	400 mm	350 mm	40 mm
TS1-1000	12.40 kg	15.50 kg	400 mm	350 mm	40 mm
TS1-2000	11.90 kg	16.20 kg	400 mm	350 mm	40 mm
TS1-3000	8.70 kg	19.10 kg	400 mm	350 mm	40 mm
TS1-4000	8.40 kg	19.40 kg	400 mm	350 mm	40 mm
TS1-6000	8.00 kg	19.80 kg	400 mm	350 mm	40 mm
<hr/>					
TS2-000	39.80 kg	9.00 kg	485 mm	430 mm	40 mm
TS2-1000	22.90 kg	27.10 kg	485 mm	430 mm	40 mm
TS2-2000	22.00 kg	28.30 kg	485 mm	430 mm	40 mm
TS2-3000	15.80 kg	33.90 kg	485 mm	430 mm	40 mm
TS2-4000	15.40 kg	34.40 kg	485 mm	430 mm	40 mm
TS2-6000	14.50 kg	35.20 kg	485 mm	430 mm	40 mm
<hr/>					
TS3-000	84.40 kg	17.50 kg	650 mm	526 mm	40 mm
TS3-1000	49.80 kg	54.90 kg	650 mm	526 mm	40 mm
TS3-2000	48.50 kg	57.00 kg	650 mm	526 mm	40 mm
TS3-3000	33.40 kg	70.40 kg	650 mm	526 mm	40 mm
TS3-4000	32.50 kg	71.40 kg	650 mm	526 mm	40 mm
TS3-6000	30.70 kg	73.20 kg	650 mm	526 mm	40 mm

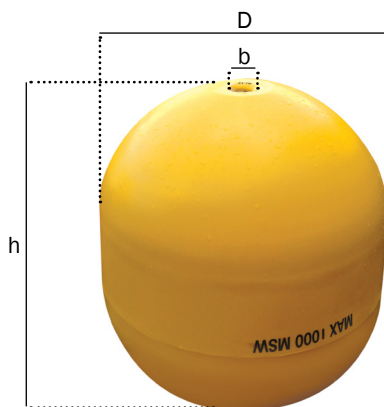

### Contact us

Trelleborg Applied Technologies delivers innovative and reliable solutions, materials and smart systems that maximizes performance for our customers. Our dedicated and highly skilled staff are always on hand to provide seamless process support from initial idea, through to delivery and beyond.



United Kingdom: +44 1706 716610  
United States: +1 774 719 1400



Email: [appliedtechnologies@trelleborg.com](mailto:appliedtechnologies@trelleborg.com)



**TRELLEBORG**

[WWW.TRELLEBORG.COM/APPLIED-TECHNOLOGIES](http://WWW.TRELLEBORG.COM/APPLIED-TECHNOLOGIES)