



TRI-CLAMP

DIN 32676/ISO 2851

TRI-CLAMP

DIN 32676/ISO 2851

MATERIAL MATIÈRE MATERIAL

 **SS** = Stainless steel **Inox**


SIZE DIMENSIONS DIMENSIONES

From DN 25 to 100 mm


FERRULE (SMS NORM)



GASKET JOINT (SMS NORM)

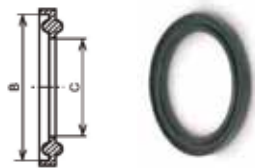

CLAMP COLLIER

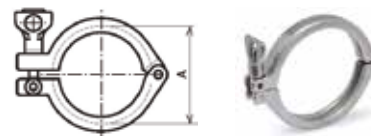


DN	d	B
25	22,5	50,5
38	35,5	50,5
51	48,5	64
63	60,5	77,5
76	72,9	91
104	100	119

Ø ext. tube	B	C
50,5	25	22,5
50,5	38	35,5
64	51	48,5
77,5	63,5	60,5
91	76,1	72,5
119	104	100



Ø tube	Ø ext. ferrule A
25 à 40	50,5
49,3 - 51 - 52	64
60,3 - 63	77,5
70 - 76,1	91
85 - 88,9	106
101,6 - 104	119

MINI CLAMP Ø34		MICRO CLAMP Ø25		CLAMP	ØA	ØB
ØA	ØB	ØA	ØB			
34	12	25	8	25	50,5	22,6
34	13,5	25	10	38	50,5	35,6
34	14	25	12	51	64	48,6
34	16	25	13,5	63,5	77,5	60,3
34	17,2	25	17,2	76,1	91	72,9
34	18			101,6	119	97,6
34	21,3	ØB à mesurer impérativement (mini et micro)		ØA = Ø sur ferrule		
34	22					

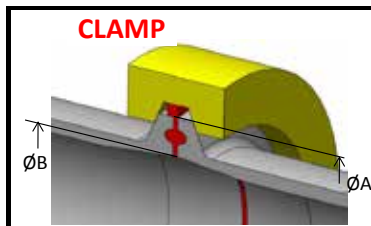

AL = Aluminium BR = Brass Laiton Latón ST = Steel Acier Acero SS = Stainless steel Inox PP = Polypropylene

 Trelleborg Fittings 2015

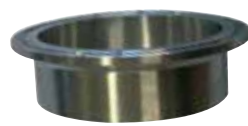			OD ferrule clamp Diam. ext. ferrule Diam. ext. clamp	ID shank Diam. douille Diam. espiga	Ref.	Notes
 Coupling. Serrated hose shank. For circlip. SMS Norm. Raccord. Douille cran-tée. Pour jonc. Norme SMS. Racor. Caña acanalada. Para anillo. Norma SMS.	PAGE 99. Circlip and ferrule. Jupe et jonc. Junta y anillo.	SS 316L	50,5	25	011 70 75	
			50,5	38	011 70 76	
			64	51	011 70 77	
			77,5	63	011 70 78	
			91	76	011 70 79	
			119	101,5	011 70 80	
 Clamp. TRI CLAMP. Collier. TRI CLAMP. Abrazadera. TRI CLAMP.		SS 304	50,5		011 82 27	
			64		011 80 97	
			77,5		011 82 28	
			91		011 82 29	
 Gasket. SMS Norm. Joint. Norme SMS. Junta. Norma SMS.		EPDM	50,5	25	510 05 59	
			50,5	38	510 05 65	
			64	51	510 02 72	
			77,5	63	510 05 66	
			91	76	510 02 73	
			119	104	510 05 67	
 Coupling. Smooth shank. With collar. SMS Norm. Raccord. Douille lisse. A collerette. Norme SMS. Racor. Caña lisa. Con cuello. Norma SMS.		SS 316L	50,5	25	510 05 46	
			50,5	38	510 05 47	
			64	50	510 05 94	
			77,5	63	510 05 95	
			91	75	510 05 96	
 For welding. SMS Norm. A souder. Norme SMS. Para soldar. Norma SMS.		SS 316L	50,5	25	510 05 68	
			50,5	38	510 05 69	
			64	51	510 02 70	
			77,5	63	510 05 70	
			91	76	510 02 71	
			119	104	510 05 71	