



GROOVED Grooved matting

29/09/2014

STANDARD MATTING

FEATURES

- Non-slip surface.
- Ribbed profiles.

ADVANTAGES

- Non-slippery
- Thermal and acoustic insulation
- Noise, vibration, and cold propagation reduction

BENEFITS

- Safety
- Comfort
- Economy

APPLICATIONS

Cutting pieces for vehicles step treads, shelves, or racks covers.

Cutting plates for protection of walls, columns, staircases, step stools, car trunks or vessels corridors.

Indoor installations.

www.trelleborg.com/elastomerlaminates



MECHANICAL, PHYSICAL AND CHEMICAL PROPERTIES

	Measured characteristics	Standard	Value
MECHANICAL			
	Rubber compound		SBR
	Hardness	ASTM D2240	70 ± 5 Shore A
	Abrasion resistance (5 N)	ISO 4649	≤ 250 mm ³


PROFILE	PATTERN
---------	---------



Fine triangular ribbed (MT)

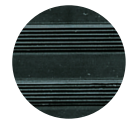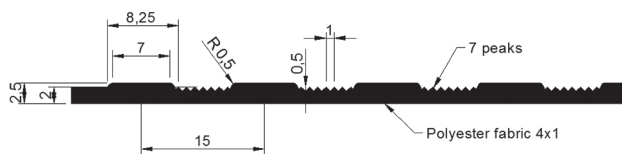

Rectangular ribbed (MR)

 

Wide ribbed (MG)

DIMENSIONS

Colour	Thickness (mm)	Width (mm)	Length (m)	Weight (kg/m ²)	Pattern
●	3 ± 0.3	1000 ± 2 %	10 ± 2 %	3.6	MT
●	3 ± 0.3	1200 ± 2 %	10 ± 2 %	3.6	MT
●	2.5 ± 0.3	1500 ± 2 %	15 ± 2 %	3.3	MR
●	5.8 ± 0.5	1000 ± 2 %	10 ± 2 %	6.9	MG
●	5.8 ± 0.5	1200 ± 2 %	10 ± 2 %	6.9	MG

IDENTIFICATION

Branding	Without.
Back face	Fabric impression.
Packaging	Rolled on cardboard tube Ø 80 mm.
Wrapping	Black polyethylene film.
Labelling	Self-adhesive label indicating product name, dimensions, area in m ² , nominal weight, and product code to allow product traceability.