



Ferrule and circlip

JUPE ET JONC CAMPANA Y ANILLO

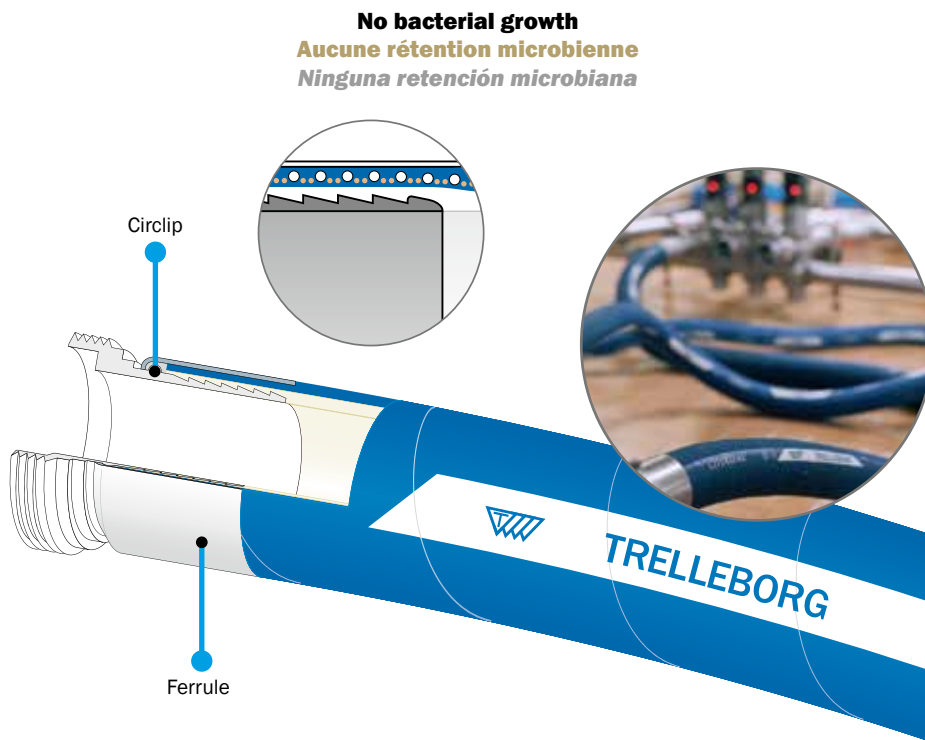
Ferrule and circlip

MATERIAL MATIÈRE MATERIAL

■ **SS** = Stainless steel **Inox**



SIZE DIMENSIONS DIMENSIONES

From DN 25 to 150 mm



AL = Aluminium BR = Brass Laiton Latón ST = Steel Acier Acero SS = Stainless steel Inox PP = Polypropylene

Trelleborg Fittings 2015

	ID coupling Diam. raccord Diam. racor	Hose OD OD tuyau OD manguera	Ref.	Notes	Ref.	Notes
						
			Ferrule		Circlip	
	25	38,5	011 69 81		011 73 61	
	32	46	510 02 76		510 02 77	
	38	52	011 69 56		011 73 62	
	45	60	510 05 07		510 05 06	
	51	65	011 67 40		011 73 63	
	51	69	011 79 68		011 73 63	
	63	77,5	011 71 46		011 73 64	
	63	82	011 82 46		011 73 64	
	70	82	510 04 41		510 04 63	
	76	91	011 71 47		011 73 65	
	76	96	011 79 70		011 73 65	
	101,5	121	011 76 68*		011 69 58*	
	125	151	510 01 35*		510 01 45*	
	150	182	510 01 48*		510 01 46*	
Ferrule and circlip. Jupe et jonc. Campana y anillo.	SS 304					
Ferrule and circlip. Euro Rapid. Jupe et jonc. Spécial Euro Rapid. Campana y anillo. Euro Rapid.	SS 304	125	151	510 08 40	510 01 45	

