



Macon

Macon

MATERIAL MATIÈRE MATERIAL

SS = Stainless steel **Inox**


SIZE DIMENSIONS DIMENSIONES

From DN 25 to 100 mm


THREAD FILETAGE ROSCA

MACON


MALE PART NEZ FILETÉ

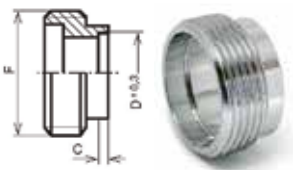

FEMALE PART PIÈCE LISSE

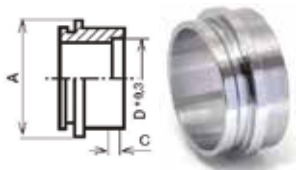

NUT ECRU

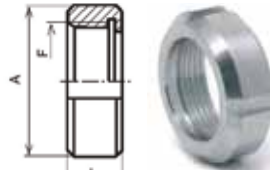

GASKET JOINT DE RACCORD



DN	D	F	c
40	43	M55x3	4,5
50	53	M67x3	4,5
60	63	M79x3,5	4,5
70	73	M90x3,5	4,5
80	83	M102x4	4,5
100	103	M125x4	4,5

D	A	c
43	50	4,5
53	62,5	4,5
63	74	4,5
73	85	4,5
83	97	4,5
103	119	4,5

A	L	F
70	24	M55x3
79	24	M67x3
94	24	M79x3,5
105	24	M90x3,5
117	26	M102x4
140	26	M125x4

A	P	S
49	42	3,5
61	52	3,5
72	62	3,5
84	72	3,5
98	82	3
118	102	3

MACON	ØA	ØB
40	50,8	55
50	63	67
60	75	79
70	85	90
80	97,2	102
100	119	125






AL = Aluminium BR = Brass Laiton Latón ST = Steel Acier Acero SS = Stainless steel Inox PP = Polypropylene

Trelleborg Fittings 2015

		ID coupling Diam. raccord Diam. racor	ID shank Diam. douille Diam. espiga	Ref.	Notes
 <p>Female. Serrated hose shank. For circlip. Femelle. Douille crantée. Pour jonc. <i>Hembra. Caña acanalada. Para anillo.</i></p>	<p>PAGE 99. Circlip and ferrule. Jupe et jonc. <i>Junta y anillo.</i></p>	SS 316L	43	38	011 70 02
			53	51	011 70 04
			63	63	011 70 00
			73	70	510 04 61
			73	76	011 70 06
			83	76	011 70 25
			103	101,5	011 70 11
 <p>Male. Serrated hose shank. For circlip. Mâle. Douille crantée. Pour jonc. <i>Macho. Caña acanalada. Para anillo.</i></p>	<p>PAGE 99. Circlip and ferrule. Jupe et jonc. <i>Junta y anillo.</i></p>	SS 316L	43	38	011 70 01
			53	51	011 70 03
			63	63	011 69 99
			73	70	510 04 62
			73	76	011 70 05
			83	76	011 70 26
 <p>Nut. Ecrou. <i>Tuerca.</i></p>		SS 304	43	38	011 69 46
			53	51	011 69 49
			63	63	011 69 98
			73	70	011 69 52
			83	76	011 70 22
			103	101,5	011 70 07
 <p>Gasket. For female MACON. Joint. Pour femelle MACON. <i>Junta. Para hembra MACON.</i></p>		NR	43		510 05 88
			53		510 05 89
			63		510 05 90
			73		510 05 91
			83		510 05 92
			103		510 05 93

AL = Aluminium BR = Brass Laiton Latón ST = Steel Acier Acero SS = Stainless steel Inox PP = Polypropylene

Trelleborg Fittings 2015

		ID coupling Diam. raccord Diam. racor	ID shank Diam. douille Diam. espiga	Ref.	Notes
	Spanner. Clé de serrage. <i>Llave de presion.</i>	SS 304		510 15 43	
	Female. Serrated hose shank. With collar. Femelle. Douille crantée. A collerette. <i>Hembra. Caña acanalada. Con cuello.</i>	SS 304	43	38	510 23 57
			53	50	510 23 53
			63	63	510 23 58
	Male. Serrated hose shank. With collar. Mâle. Douille crantée. A collerette. <i>Macho. Caña acanalada. Con cuello.</i>	SS 304	43	38	510 23 62
			53	50	510 23 63
			63	63	510 23 64
	Female for welding. Femelle à souder. <i>Hembra para soldar.</i>	SS 316L	43	43	510 23 18
			53	53	510 23 19
			63	63	510 23 20
			73	73	510 23 21
			83	83	510 23 22
	Male for welding. Mâle à souder. <i>Macho para soldar.</i>	SS 316L	103	103	510 23 23
			43	43	510 23 24
			53	53	510 23 25
			63	63	510 23 26
			73	73	510 23 27
			83	83	510 23 28

For any other need, do consult us.
 Pour tout autre besoin, nous consulter.
 Para otras necesidades, consultarnos.