

# Safety clamp

## DIN 2817

COLLIER 1/2 COQUILLE ABRAZADERA

## Safety clamp DIN 2817



---

### MATERIAL MATIÈRE MATERIAL

■ **AL** = Aluminium



■ **SS** = Stainless steel **Inox**

---

### SIZE DIMENSIONS DIMENSIONES

From DN 30 to 200 mm

---

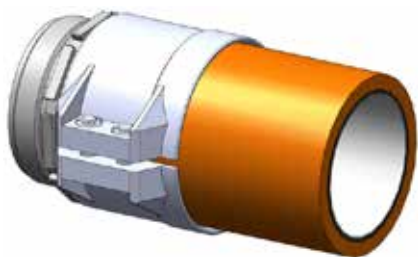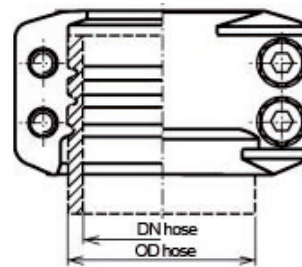

■ AL = Aluminium 
 ■ BR = Brass **Laiton Latón**
■ ST = Steel **Acier Acero**
■ SS = Stainless steel **Inox**
■ PP = Polypropylene

## Trelleborg Fittings 2015

		OD hose Diam. ext. tuyau Diam. ext. mang.	DN hose	Ref.	Notes
13 * 5		22 - 24	13	011 75 61	
19 * 6		30 - 33	19	011 34 72	
25 * 6		36 - 39	25	073 20 19	
25 * 8		40 - 43	25	011 75 62	
32 * 6		43 - 46	32	073 20 20	
32 * 8		47 - 50	32	011 75 63	
38 * 5		47 - 49	38	510 89 77	
38 * 6,5		50 - 52	38	073 16 63	
38 * 8		53 - 56	38	011 17 49	
38 * 10		57 - 60	38	011 20 11	
40 * 7		54 - 58	40	011 19 85	
50 * 2		52 - 56	50	510 31 75	
50 * 6		61 - 63	50	510 10 18	
50 * 8		64 - 67	50	073 16 64	
50 * 10		69 - 71	50	011 18 86	
63 * 6		74 - 76	65	510 29 76	
63 * 8 - 65 * 7		78 - 82	65	011 17 50	
65 * 10		84 - 87	65	011 18 91	
75 * 8		89 - 93	75	073 16 66	
75 * 10		94 - 97	75	073 20 12	
75 * 12		98 - 101	75	011 75 64	
80 * 8		94 - 97	80	011 17 51	
80 * 10		99 - 102	80	011 18 95	
100 * 8		114 - 119	100	073 16 67	
100 * 10		118 - 122	100	011 18 99	
100 * 12		122 - 126	100	011 12 49	
100 * 14		126 - 130	100	011 15 82	
100 * 16		130 - 134	100	011 36 52	
125 * 10		143 - 148	125	011 17 52	
125 * 15		153 - 158	125	011 75 65	
150 * 10		168 - 174	150	011 17 53	
150 * 13		174 - 180	150	011 75 66	
150 * 15		178 - 184	150	011 17 54	
200 * 12		222 - 229	200	011 17 56	



AL

■ AL = Aluminium  
 ■ BR = Brass **Laiton Latón**  
 ■ ST = Steel **Acier Acero**  
 ■ SS = Stainless steel **Inox**  
 ■ PP = Polypropylene

## Trelleborg Fittings 2015

		OD hose Diam. ext. tuyau Diam. ext. mang.	DN hose	Ref.	Notes	
	13 * 5	22 - 24	13	011 75 67		
	19 * 6	30 - 33	19	011 75 68		
	25 * 6	36 - 39	25	011 75 69		
	32 * 6	43 - 46	32	011 75 70		
	38 * 6,5	50 - 52	38	011 75 71		
	50 * 6	61 - 63	50	510 89 76		
	50 * 8	64 - 67	50	011 75 72	SS 316	
	63 * 6	73 - 77	63	510 89 75		
	65 * 7	78 - 82	65	011 75 73		
	75 * 6,5	86 - 90	75	510 31 81		
	75 * 8	89 - 93	75	011 75 74		
	100 * 8	114 - 119	100	011 75 75		
			13 - 38		M6-STOP	
	 <p>Autoblock nut. <b>Ecrou autobloquant.</b> <i>Tuerca autoblocante.</i></p>		50 - 80		M8-STOP	SS
				100 - 125		M10-STOP
			150 - 200		M12-STOP	