

Storz

DIN 14 321/322/323/307/308/309

Storz
DIN 14 321/322/323/307/308/309

MATERIAL MATIÈRE MATERIAL

AL = Aluminium

SIZE DIMENSIONS DIMENSIONES


DN 50/80/100 mm

THREAD FILETAGÉ ROSCA

BSPP/NF ISO 228-1

GASKETS JOINTS JUNTA

NBR

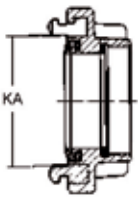

DN	KA
52-C	66
75-B	89
110-A	133

AL = Aluminium
 BR = Brass *Laiton Latón*
 ST = Steel *Acier Acero*
 SS = Stainless steel *Inox*
 PP = Polypropylene

Trelleborg Fittings 2015

			ID coupling Diam. raccord Diam. racor	ID shank Diam. douille Diam. espiga	Ref.	Notes
 Secure female thread. Fileté femelle sécurisé. <i>Rosca hembra securi-</i> <i>sado.</i>	Type C.		52	2"	510 15 37	
	Type B.	AL	75	3"	510 15 38	
	Type A.		110	4"	510 15 39	
 Female thread. Fileté femelle. <i>Rosca hembra.</i>	Type C. DIN 14 307.		52	2"	510 17 71	
	Type B. DIN 14 308.	AL	75	3"	510 17 72	
	Type A. DIN 14 309.		110	4"	510 17 73	
 Swivel female thread. Fileté femelle tournant. <i>Rosca hembra giratorio.</i>	Type C.		52	2"	510 50 96	
	Type B.	AL	75	3"	510 50 97	
	Type A.		110	4"	510 17 74	