

 
The background of the top half of the page is a close-up photograph of a green flexible hose connected to a metal tank. The hose is curved, and the metal surface of the tank is visible in the background.

Tankwagen

DIN 28 450/EN 14 420-6

Tankwagen

DIN 28 450/EN 14 420-6



MATERIAL MATIÈRE MATERIAL

- BR** = Brass **Laiton Latón**
- SS** = Stainless steel **Inox**

SIZE DIMENSIONS DIMENSIONES

DN 50/80/100 mm


THREAD FILETAGE ROSCA

BSPP/NF ISO 228-1

GASKETS JOINTS JUNTA


NBR/CSM

VK

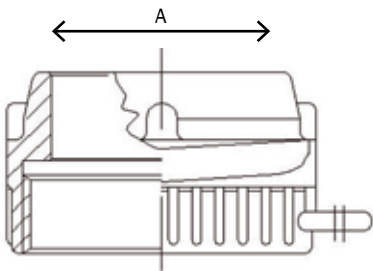

DN	A
50	48,5
80	76
100	95

MK

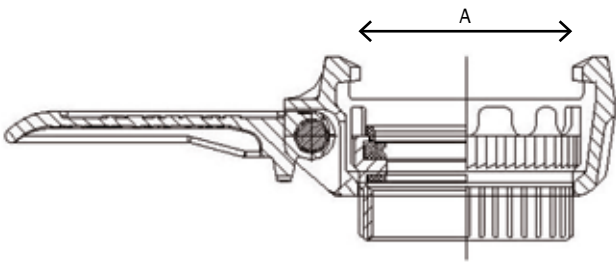

DN	A
50	71
80	102
100	129

AL = Aluminium
 BR = Brass *Laiton Latón*
 ST = Steel *Acier Acero*
 SS = Stainless steel *Inox*
 PP = Polypropylene

Trelleborg Fittings 2015

		ID coupling Diam. raccord Diam. racor	ID shank Diam. douille Diam. espiga	Ref.	Notes
 MK/Female thread. With handle. MK/Fileté femelle. Avec poignée. MK/Rosca hembra. Con punado.	BR	50		510 15 06	
		80		510 15 07	
		100		510 15 08	
	SS 316	50		510 15 04	
		80		510 15 05	
		100		510 15 93	
 VK/Female thread. VK/Fileté femelle. VK/Rosca hembra.	BR	50		510 15 11	
		80		510 15 12	
		100		510 15 13	
	SS 316	50		510 15 09	
		80		510 15 10	
		100		510 15 94	
 MB cap. MB bouchon. MB tapon.	BR	50		510 15 17	
		80		510 15 18	
		100		510 15 19	
	SS 316	50		510 15 14	
		80		510 15 15	
		100		510 15 16	
 VB cap. VB bouchon. VB tapon.	BR	50		510 15 23	
		80		510 15 24	
		100		510 15 25	
	SS 316	50		510 15 20	
		80		510 15 21	
		100		510 15 22	