



Washing gun

PISTOLETS DE LAVAGE PISTOLA DE LAVADO

Washing gun

MATERIAL MATIÈRE MATERIAL

BR = Brass **Laiton Latón**

SS = Stainless steel **Inox**

With EPDM cover.

Avec revêtement EPDM.

Con EPDM revestimiento.

SIZE DIMENSIONS DIMENSIONES


DN 1/2"

WATER FLOW DÉBIT D'EAU SALIDA DE AGUA

Water flow in l/min with totally pulled trigger.



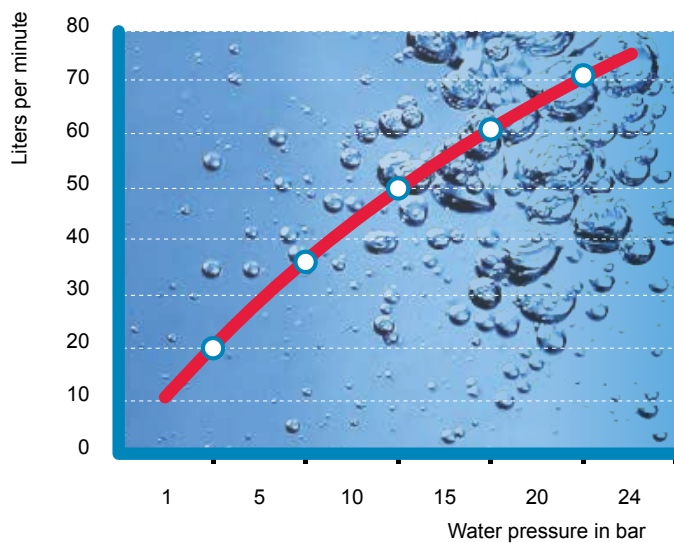

Débit mesuré en l/min à ouverture maximale.

Salida de agua en l/min con apertura máxima.






AL = Aluminium BR = Brass Laiton Latón ST = Steel Acier Acero SS = Stainless steel Inox PP = Polypropylene

Trelleborg Fittings 2015

		ID coupling Diam. raccord Diam. racor	ID shank Diam. douille Diam. espiga	Ref.	Notes
	Blue. Eco. 95°C. 24 bar. Bleu. Eco. 95°C. 24 bar. Azul. Eco. 95°C. 24 bar.	BR	1/2"	510 10 70	
	Blue. Standard. 95°C. 24 bar. Bleu. Standard. 95°C. 24 bar. Azul. Standard. 95°C. 24 bar.	BR	1/2"	011 76 70	
	Pack of 20 * 011 76 70. Pack de 20 * 011 76 70. Pack de 20 * 011 76 70.	BR	1/2"	510 00 40	
	Blue. With handle protection. 95°C. 24 bar. Bleu. Avec protection main. 95°C. 24 bar. Azul. Con proteccion de la mano. 95°C. 24 bar.	BR	1/2"	510 10 13	
	Blue. Standard. 95°C. 24 bar. Bleu. Standard. 95°C. 24 bar. Azul. Standard. 95°C. 24 bar.	BR Chromated	1/2"	510 00 33	
	Blue. Light. 50°C. 12 bar. Bleu. Léger. 50°C. 12 bar. Azul. Lígero. 50°C. 12 bar.	PVC	1/2"	510 71 21	

■ AL = Aluminium
 ■ BR = Brass **Laiton Latón**
 ■ ST = Steel **Acier Acero**
 ■ SS = Stainless steel **Inox**
 ■ PP = Polypropylene

Trelleborg Fittings 2015

		ID coupling Diam. raccord Diam. racor	ID shank Diam. douille Diam. espiga	Ref.	Notes
 <p>Blanc. With handle protection. 95 °C. 24 bar. Blanc. Avec protection main. 95 °C. 24 bar. Blanco. Con proteccion de la mano. 95 °C. 24 bar.</p>	BR Chromated	1/2"		510 07 27	
 <p>Red. With handle protection. 95 °C. 24 bar. Rouge. Avec protection main. 95 °C. 24 bar. Rojo. Con proteccion de la mano. 95 °C. 24 bar.</p>	SS 316	1/2"		510 05 26	
 <p>Black. High flow. 95 °C. 24 bar. Noir. Grand débit. 95 °C. 24 bar. Negro. Gran caudal. 95 °C. 24 bar.</p>	BR	1/2"		510 10 64	
 <p>Spray. Blue. 80 °C. 16 bar. Lance. Bleue. 80 °C. 16 bar. Spray. Azul. 80 °C. 16 bar.</p>	BR	1/2"		510 50 66	
 <p>Repare Pack. Except for 510 10 70. Pack réparation. Sauf pour 510 10 70. Pack reparación pistola. No para 510 10 70.</p>	SS 316			010 00 15	