



Express

NFE 29 573

Express NFE 29 573



MATERIAL MATIÈRE MATERIAL

- **BR** = Brass *Laiton Latón*
- **ST** = Steel *Acier Acero*
- **SS** = Stainless steel *Inox*

SIZE DIMENSIONS DIMENSIONES


From DN 1/4" to DN 1" 1/4

THREAD FILETAGE ROSCA

BSPP/NF ISO 228-1

GASKETS JOINTS JUNTA

NBR

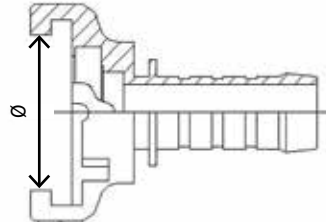

DN	Ø
1/4"	40,5
1/2"	
3/4"	
1"	
1"1/4"	




AL = Aluminium BR = Brass Laiton Latón ST = Steel Acier Acero SS = Stainless steel Inox PP = Polypropylene

Trelleborg Fittings 2015

		ID coupling Diam. raccord Diam. racor	ID shank Diam. douille Diam. espiga	Ref.	Notes
 <p>Serrated hose shank. NBR gasket. Annelé. Joint NBR. <i>Acanalado. Junta NBR.</i></p>	BR		9	510 23 13	
			13	510 23 12	
			16	510 17 55	
			19	510 17 56	
			25	510 17 57	
 <p>Female thread. NBR gasket. Fileté femelle. Joint NBR. <i>Rosca hembra. Junta NBR.</i></p>	BR	1/4"		510 23 09	
		1/2"		510 17 52	
		3/4"		510 17 53	
		1"		510 17 54	
		1"1/4		510 51 03	
 <p>Male thread. NBR gasket. Fileté mâle. Joint NBR. <i>Rosca macho. Junta NBR.</i></p>	BR	1/4"		510 23 06	
		1/2"		510 17 49	
		3/4"		510 17 50	
		1"		510 17 51	
		1"1/4		510 23 08	
 <p>Cap Express. NBR gasket. Bouchon Express. Joint NBR. <i>Tapon Express. Junta NBR.</i></p>	BR			510 23 17	
 <p>Serrated hose shank. NBR gasket. Annelée. Joint NBR. <i>Acanalado. Junta NBR.</i></p>	SS 316		16	510 15 55	
			19	510 15 56	
			25	510 15 57	
 <p>Female thread. NBR gasket. Fileté femelle. Joint NBR. <i>Rosca hembra. Junta NBR.</i></p>	SS 316	1/2"		510 15 52	
		3/4"		510 15 53	
		1"		510 15 54	
 <p>Male thread. NBR gasket. Fileté mâle. Joint NBR. <i>Rosca macho. Junta NBR.</i></p>	SS 316	1/2"		510 15 49	
		3/4"		510 15 50	
		1"		510 15 51	
 <p>Express BW. NBR gasket. Express BW. Joint NBR. <i>Express BW. Junta NBR.</i></p>	SS 316		33,7	510 22 59	
 <p>Cap Express. NBR gasket. Bouchon Express. Joint NBR. <i>Tapon Express. Junta NBR.</i></p>	SS 316			510 15 58	

■ AL = Aluminium
 ■ BR = Brass *Laiton Latón*
 ■ ST = Steel *Acier Acero*
 ■ SS = Stainless steel *Inox*
 ■ PP = Polypropylene

Trelleborg Fittings 2015

		ID coupling Diam. raccord Diam. racor	ID shank Diam. douille Diam. espiga	Ref.	Notes	
	Gasket. Joint. <i>Junta.</i>	FPM		510 15 59		
		NBR		510 23 05		
	Ferrule (20 pieces packaging). Jupe (par 20 pièces). <i>Campana (para 20 piezas).</i>	ST	19	011 78 95		
	Clamp. Collier serrage. <i>Abrazadera.</i>	ST	N°15	14 - 16	510 22 96	
			N°17	16 - 18	510 22 97	
			N°20	19 - 21	510 22 98	
			N°23	22 - 24	510 22 99	
			N°26	25 - 27	510 23 00	
			N°29	28 - 30	510 23 01	
			N°32	31 - 33	510 23 02	
			N°36	35 - 37	510 23 03	
			N°38	37 - 39	510 23 04	