



Helicoidal hose shank

DOUILLE HÉLICOÏDALE CANA HELICOIDAL

Helicoidal hose shank


MATERIAL MATIÈRE MATERIAL

- AL** = Aluminium
- BR** = Brass **Laiton Latón**
- SS** = Stainless steel **Inox**
- PP** = Polypropylene

SIZE DIMENSIONS DIMENSIONES

From DN 25 to 100 mm



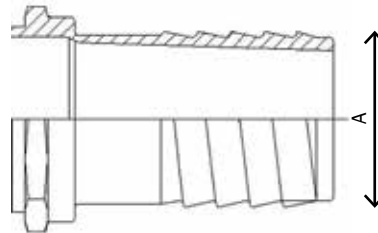


GASKETS JOINTS JUNTA



DN	A
25	27,5
32	35
40	43
50	53
65	67,5
80	83
100	106

■ AL = Aluminium
 ■ BR = Brass **Laiton Latón**
■ ST = Steel **Acier Acero**
■ SS = Stainless steel **Inox**
■ PP = Polypropylene

Trelleborg Fittings 2015

		ID coupling Diam. raccord Diam. racor	ID shank Diam. douille Diam. espiga	Ref.	Notes
 <p>Guillemin.</p>	AL	1"1/2	40	510 16 00	
		2"	50	510 15 98	
		2"1/2	65	510 15 99	
		3"	80	510 16 01	
		4"	100	510 16 02	
 <p> Pack Guillemin. Ferrule SS 304. Pack Guillemin. Jupe Inox 304. Pack Guillemin. Campana Inox 304. </p>	AL	40	40	011 62 18	
		50	50	011 01 28	
		65	65	011 01 29	
		80	80	011 01 30	
		100	100	011 01 31	
 <p> Guillemin. Without ears. Guillemin. Sans oreilles. Guillemin. Sin orejas. </p>	AL	50	50	510 51 38	
		65	65	510 51 39	
		80	80	510 51 40	
 <p> Male thread. Fileté mâle. Rosca macho. </p>	AL	1"1/2	40	510 16 18	
		2"	50	510 16 07	
		2"1/2	65	510 16 08	
		3"	80	510 16 09	
		4"	100	510 16 10	
 <p> Pack male thread. Ferrule SS 304. Pack fileté mâle. Jupe Inox 304. Pack rosca macho. Campana Inox 304. </p>	AL	1"1/2	40	011 62 78	
		2"	50	011 01 43	
		2"1/2	65	011 01 44	
		3"	80	011 01 45	
		4"	100	011 01 46	






AL = Aluminium BR = Brass **Laiton Latón** ST = Steel **Acier Acero** SS = Stainless steel **Inox** PP = Polypropylene

Trelleborg Fittings 2015

		ID coupling Diam. raccord Diam. racor	ID shank Diam. douille Diam. espiga	Ref.	Notes
 <p>Male thread. Fileté mâle. <i>Rosca macho.</i></p>	SS 316	1 "	25	510 16 11	
		1"1/4	32	510 16 12	
		1"1/2	40	510 16 13	
		2"	50	510 16 14	
		2"1/2	65	510 16 15	
		3"	80	510 16 16	
		4"	100	510 16 17	
 <p>Pack male thread. Ferrule SS 304. Pack fileté mâle. Jupe Inox 304. <i>Pack rosca macho. Campana Inox 304.</i></p>	SS 316	1 "	25	011 63 30	
		1"1/4	32	011 63 28	
		1"1/2	40	011 63 26	
		2"	50	011 01 50	
		2"1/2	65	011 01 51	
		3"	80	011 01 52	
		4"	100	011 01 12	
 <p>Guillemin.</p>	SS 316	40	40	510 22 71	
		50	50	510 16 03	
		65	65	510 16 04	
		80	80	510 16 05	
		100	100	510 16 06	
 <p>Pack Guillemin. Ferrule SS 304. Pack Guillemin. Jupe Inox 304. <i>Pack Guillemin. Campana Inox 304.</i></p>	SS 316	40	40	510 24 15	
		50	50	011 01 36	
		65	65	510 15 03	
		80	80	011 01 38	
		100	100	011 04 85	
 <p>Guillemin. Secure. Guillemin. Sécurisé. <i>Guillemin. Securitizado.</i></p>	SS 316	50	50	510 23 44	
		80	80	510 12 39	
 <p>For welding BW. A souder BW. <i>Para soldar BW.</i></p>	SS 316	48,3	40	510 23 89	
		60,3	50	510 23 90	
		88,9	80	510 23 91	
		114,3	100	510 23 92	



■ AL = Aluminium
 ■ BR = Brass **Laiton Latón**
 ■ ST = Steel **Acier Acero**
 ■ SS = Stainless steel **Inox**
 ■ PP = Polypropylene

Trelleborg Fittings 2015

		ID coupling Diam. raccord Diam. racor	ID shank Diam. douille Diam. espiga	Ref.	Notes
 <p>Male thread. Fileté mâle. <i>Rosca macho.</i></p>	BR	2"	50	510 16 24	
		3"	80	510 16 25	
 <p>Guillemin.</p>	BR	50	50	510 16 23	
		80	80	510 16 20	
 <p>Male thread. Fileté mâle. <i>Rosca macho.</i></p>	PP	2"	50	510 24 05	
		3"	80	510 24 06	
 <p>Pack male thread. Ferrule SS 304. Pack fileté mâle. Jupe Inox 304. <i>Pack rosca macho. Campana Inox 304.</i></p>	PP	2"	50	510 24 03	
		3"	80	510 24 04	
 <p>Gasket. Joint. <i>Junta.</i></p>	NBR	25		011 62 68	
		32		011 62 67	
		40		011 62 66	
		50		011 45 25	
		65		011 45 28	
		80		011 45 31	
	FPM	100		011 45 34	
		40		510 23 54	
		50		510 91 07	
		80		510 20 63	

AL = Aluminium BR = Brass **Laiton Latón** ST = Steel **Acier Acero** SS = Stainless steel **Inox** PP = Polypropylene

Trelleborg Fittings 2015

		ID coupling Diam. raccord Diam. racor	ID shank Diam. douille Diam. espiga	Ref.	Notes	
 <p>Ferrule. Jupe. Campana.</p>		AL		40	45 * 60 * 68 (1,5)	011 62 69
				50	55 * 69 * 63 (1,5)	011 73 75
				80	84 * 102 * 75 (2)	011 73 49
				100	107 * 131 * 120 (2)	011 73 50
		SS 304		25	30 * 43 * 48 (1,5)	011 62 72
				32	36 * 53 * 46 (1,5)	011 62 71
				40	45 * 60 * 68 (1,5)	011 62 70
				50	55 * 69 * 63 (1,5)	011 02 79
				65	68 * 89 * 80 (1,5)	011 02 80
				80	84 * 102 * 75 (1,5)	011 02 81
100	107 * 131 * 120 (2)	011 45 35				
 <p>Adhesive tape. Ruban adhésif. Cinta adhesiva.</p>		Width 19 mm. Lg 50 m. Largeur 19 mm. Lg 50 m. Ancho 19 mm. Lg 50 m.		20 - 40	510 51 35	
		Width 38 mm. Lg 50 m. Largeur 38 mm. Lg 50 m. Ancho 38 mm. Lg 50 m.		50 - 100	510 51 37	