

Steam hose couplings

EN 14 423/DIN 2826

RACCORDS VAPEUR RACOR VAPOR

Steam hose couplings EN 14 423/DIN 2826

MATERIAL MATIÈRE MATERIAL

■ ST = Steel **Acier Acero**

SIZE DIMENSIONS DIMENSIONES

From DN 1/2" to DN 2"

THREAD FILETAGE ROSCA

BSPP/NF ISO 228-1

GASKETS JOINTS JUNTA

Novapress®

Steam

Vapeur

Vapor

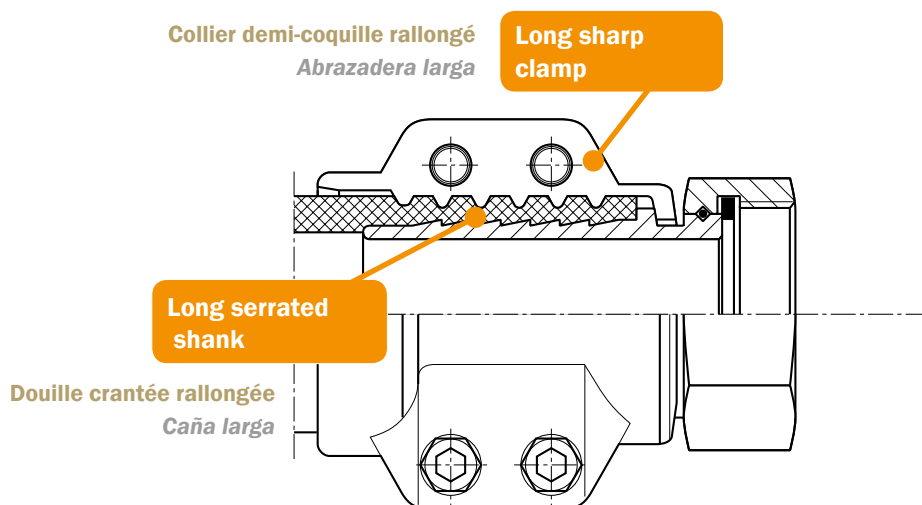
+ 210 °C

Hot water

Eau chaude



Agua caliente

+ 120 °C



■ AL = Aluminium
 ■ BR = Brass **Laiton Latón**
 ■ ST = Steel **Acier Acero**
 ■ SS = Stainless steel **Inox**
 ■ PP = Polypropylene

Trelleborg Fittings 2015

		ID coupling Diam. raccord Diam. racor	ID shank Diam. douille Diam. espiga	Ref.	Notes
 <p> Pack male thread. With brass collar. Pack fileté mâle. Avec collier laiton. <i>Pack rosca macho. Con abrazadera laton.</i> </p>	ST	1/2"	13	011 66 14	
		3/4"	19	011 69 30	
		1"	25	011 75 49	
		1"1/4	32	011 75 50	
		1"1/2	38	011 75 51	
		2"	50	011 75 52	
 <p> Pack female thread. With brass collar. Novapress® gasket. Pack fileté femelle. Avec collier laiton. Joint Novapress®. <i>Pack rosca hembra. Con abrazadera laton. Junta Novapress®.</i> </p>	ST	1/2"	13	011 75 53	
		3/4"	19	011 75 54	
		1"	25	011 75 55	
		1"1/4	32	011 75 56	
		1"1/2	38	011 75 57	
		2"	50	011 75 58	