




GUTTELING SLINGS



COUPLINGS & ACCESSORIES

Composite hoses/Slings

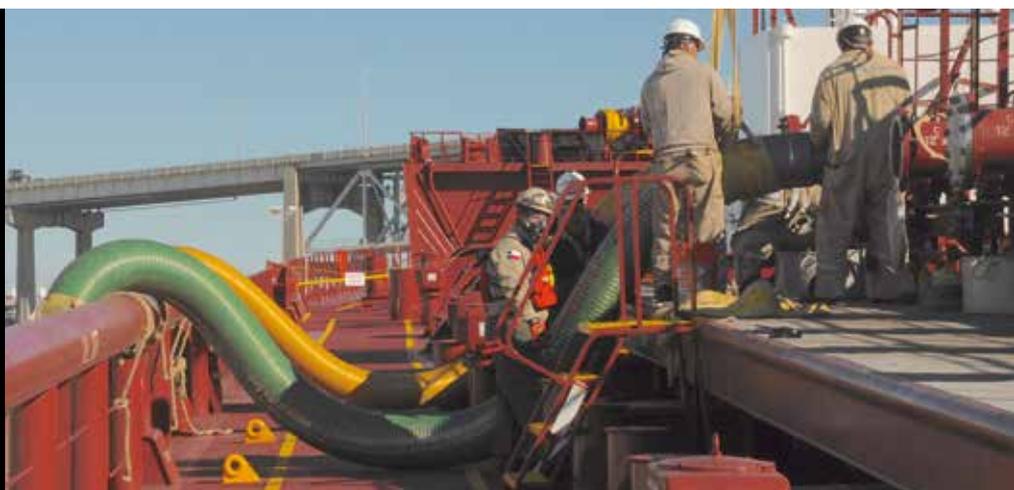

HOSE HANDLING SLINGS

In the case of Gutteling 'Heavy Duty' loading and unloading hoses (ship to shore applications), the use of at least one wide support sling is recommended for hoses with a maximum length of 6 mtr and an inner diameter between 100 m/m and 300 m/m. For longer hoses, at least two wide support slings per hose must be used and in the case of diameters above 200 m/m the use of a so-called 'saddle' is required.

All hose handling slings can be delivered with CE-certificate.

Never use ropes as severe hose damage may be the result.



Hose diameter	4"	6"	8"	10"	12"
Max. hose length	6m/20 ft				

WIDE SUPPORT HOSEBUNS

Gutteling hosebuns are composed of a red polymer and are used with latex-treated yellow web slings uniquely engineered for each specific model of hosebun. Sling rated capacities are established using a 5:1 safety factor. All slings are used in a choker hitch position to eliminate hose slippage.

All hosebuns can be delivered with CE-certificate.

Never use ropes as severe hose damage will be the result.



Hose size	3"	4"	6"	8"	10"	12"
Hosebun model	HB300	HB400	HB600	HB800	HB1000	HB1200
Length (inches)	12,75	11,5	21,5	30,5	40,75	40,75
Weight (lbs.)	4,25	5	17	37	62	62
Sling width (inches)	1,97	1,97	3,94	5,91	7,09	9,84
Sling length (inches)	14,75	14,75	22,5	45,7	48,9	59,1
Rated capacity (lbs.)	2000	2000	8000	12000	15000	15000