


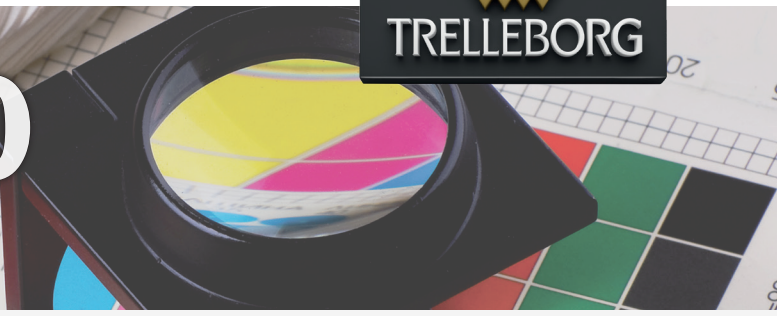

# Rollin<sup>®</sup> MPR40




## Key performance

- Improved reboundability and striking absorption
- Increased flexibility, easy handling and machine set up
- Improvement of half tone reproduction and overall print quality
- Enhanced smash resistance
- Increased blanket lifetime

## MAIN APPLICATION

Commercial Sheetfed

**Rollin MPR40 is available in 3 ply, 1,95 mm thickness.**

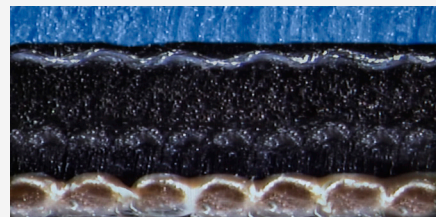

**Rollin MPR40**

## ✓ The product at a glance

<b>INK COMPATIBILITY</b>	Hybrid
<b>PRINTING SURFACE COLOUR</b>	Light blue
<b>THICKNESS (mm)</b>	1,95
<b>AVERAGE LOAD VALUE N/cm<sup>2</sup> @ 0,23 mm Indentation</b>	240
<b>SURFACE ROUGHNESS (Ra micron)</b>	0,6

**FOR ANY FURTHER DETAILS AND FOR A QUOTATION  
PLEASE REFER TO YOUR SALES MANAGER  
OR EMAIL US AT: [printingsm@trelleborg.com](mailto:printingsm@trelleborg.com)**