

Zenith


Key performance

- Specifically designed for UV applications
- Increased blanket lifetime
- Reduced downtime due to less blanket changes
- Improved Ink release and cleaning
- Sticky back blanket is available for business forms and labels printing

MAIN APPLICATION

Sheetfed

Vulcan Zenith is available in 3 ply, 1,96 mm thickness.

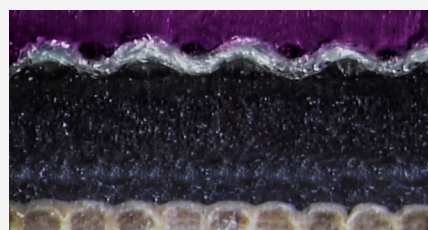

Vulcan Zenith

The product at a glance

INK COMPATIBILITY	Hybrid
PRINTING SURFACE COLOUR	Blue
THICKNESS (mm)	1,96
AVERAGE LOAD VALUE N/cm² @ 0,23 mm Indentation	240
SURFACE ROUGHNESS (Ra micron)	1,2
ELONGATION (%)	<0,9
TENSILE STRENGTHS (N/mm)	>60
WATER & SOLVENT PROTECTION	No
ADDITIONAL INFORMATION	
APPLICATIONS	All-round sheetfed blanket

**FOR ANY FURTHER DETAILS AND FOR A QUOTATION
PLEASE REFER TO YOUR SALES MANAGER
OR EMAIL US AT: printingsm@trelleborg.com**