



Printec 640-B


Key Performance

- Ideal for newspaper high speed presses
- Designed with Feed-0 Technology: optimum paper feed tension; reduced risks of paper breaks; easier control of colour register during the start-up; improved paper wastage control

MAIN APPLICATION

Newspaper Coldset

Printec 640-B is available in 4 ply 1,96 mm thickness

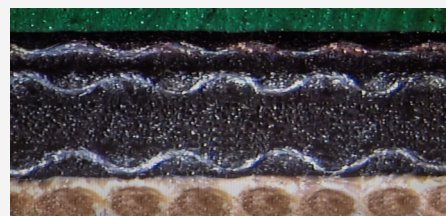

Printec 640-B



The product at a glance

INK COMPATIBILITY	Hybrid
PRINTING SURFACE COLOUR	Green
THICKNESS (mm)	1,96
AVERAGE LOAD VALUE N/cm² @ 0,20 mm Indentation	250
SURFACE ROUGHNESS (µm)	1,0
ELONGATION (%)	< 0,9
TENSILE STRENGTH (N/mm)	>75
WATER & SOLVENT PROTECTION	Yes
ADDITIONAL INFORMATION	
APPLICATIONS	Newspaper and 4 ply web

**FOR ANY FURTHER DETAILS AND FOR A QUOTATION
PLEASE REFER TO YOUR SALES MANAGER
OR EMAIL US AT: printingsm@trelleborg.com**