

Rollin[®]Type150


Key performance

- Consistent throw length, uniform nip pressure, easy washup
- The best adhesive in the market to avoid creeping and lifting
- Clean and easy removal from the cylinder
- Improved blanket lifetime

MAIN APPLICATION

Business Forms, labels

Rollin Type150 available in multiple ply type and multiple thickness.

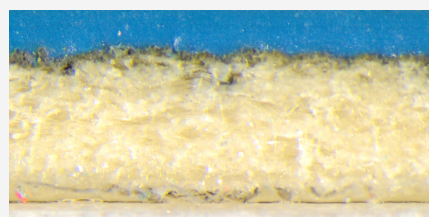

Rollin Type150



The product at a glance

INK COMPATIBILITY	UV
PRINTING SURFACE COLOUR	Light Blue
THICKNESS (mm)	0,90-0,94; 0,98-1,00; 1,04-1,06
AVERAGE LOAD VALUE N/cm ² @ 0,23 mm Indentation	Not Applicable
SURFACE ROUGHNESS (Ra micron)	1,7
ADDITIONAL INFORMATION	
APPLICATIONS	ADHESIVE

**FOR ANY FURTHER DETAILS AND FOR A QUOTATION
PLEASE REFER TO YOUR SALES MANAGER
OR EMAIL US AT: printingsm@trelleborg.com**