

# vulcan<sup>®</sup> UV


## Key performance

- Specifically designed for UV applications
- Increased blanket lifetime
- Reduced downtime due to less blanket changes
- Sticky back blanket is available for business forms and labels printing

## MAIN APPLICATION

UV

Vulcan UV is available in 3 ply, 1,71 - 1,96 mm thickness

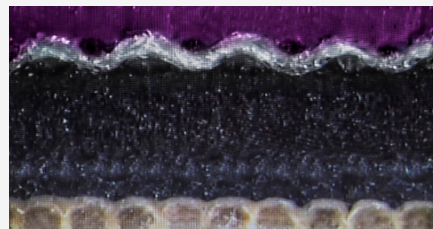

Vulcan UV

## ✓ The product at a glance

<b>INK COMPATIBILITY</b>	UV
<b>PRINTING SURFACE COLOUR</b>	Purple
<b>THICKNESS(mm)</b>	1,71 / 1,96
<b>AVERAGE LOAD VALUE N/cm<sup>2</sup> @ 0,23 mm Indentation</b>	260
<b>SURFACE ROUGHNESS (Ra micron)</b>	0,8
<b>ELONGATION (%)</b>	<0,9
<b>TENSILE STRENGTH (N/mm)</b>	>60
<b>ADDITIONAL INFORMATION</b>	
<b>MORE VERSIONS</b>	Adhesive on request

**FOR ANY FURTHER DETAILS AND FOR A QUOTATION  
PLEASE REFER TO YOUR SALES MANAGER  
OR EMAIL US AT: [printingsm@trelleborg.com](mailto:printingsm@trelleborg.com)**