

Rollin® PT600


Key performance

- Chemical resistant surface compatible with UV and conventional inks
- Flexible carcass for easy press side handling
- Increased smash resistance
- Ground surface for consistent gauge, sharp halftones and dense solids

MAIN APPLICATION

Sheetfed, folding carton, commercial/coldset web

Rollin PT600 is available in 3 / 4 ply, .067" ± .001" / .077" ± .001" thickness.

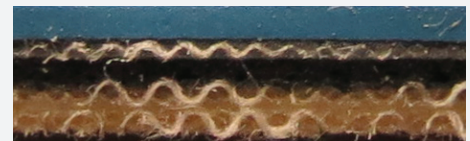

The product at a glance

INK COMPATIBILITY	Conventional and Hybrid
PRINTING SURFACE COLOR	Light Blue
NOMINAL THICKNESS (Inches)	.067" ± .001" (1.71mm ± 0.02) 3 ply/ .077" ± .001" (1.96mm ± 0.02) 4 ply
AVERAGE LOAD VALUE N/cm² @ 0.23 mm	200
SURFACE ROUGHNESS	0,9
ELONGATION (%)	Max. 7
TENSILE STRENGTH (N/MM)	Min. 60
WATER & SOLVENT PROTECTION	No
HARDNESS	78 Shore A
BLANKET CONSTRUCTION	Compressible

**FOR ANY FURTHER DETAILS AND FOR A QUOTATION
PLEASE REFER TO YOUR SALES MANAGER
OR EMAIL US AT: printing@trelleborg.com**