



Rollin[®] Polycell Plus


Key performance

- High printing quality
- Improved load consistency batch to batch
- Easy blanket set up on machine
- Implements all benefits of the **Dynatech System**:
 - Better vibration absorption
 - Less gears streaking marks
 - Higher paper smash resistance
 - Blanket consistency
 - Excellent reboundability

MAIN APPLICATION

Commercial Sheetfed,
Packaging

**Rollin Polycell is available in
3-ply, 1,96 mm thickness**

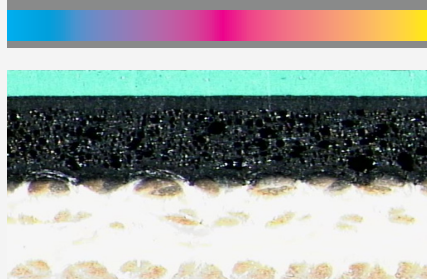

Rollin Polycell Plus

✓ The product at a glance

INK COMPATIBILITY	Hybrid
PRINTING SURFACE COLOUR	Green
THICKNESS (mm)	1,96
AVERAGE LOAD VALUE N/cm² @ 0,23 mm Indentation	250
SURFACE ROUGHNESS (Ra micron)	0,8
TENSILE STRENGTH (N/mm)	>67
WATER & SOLVENT PROTECTION	Yes
ADDITIONAL INFORMATION	
ADVANCED TECHNOLOGY	Dynatech System

**FOR ANY FURTHER DETAILS AND FOR A QUOTATION
PLEASE REFER TO YOUR SALES MANAGER
OR EMAIL US AT: printingsm@trelleborg.com**