



vulcan[®] UV


Key performance

- Specifically designed for UV applications
- Increased blanket lifetime
- Reduced downtime due to less blanket changes
- Sticky back blanket is available for business forms and labels printing

MAIN APPLICATION

Sheetfed

Vulcan UV is available in 3 ply, 1,96 mm thickness.

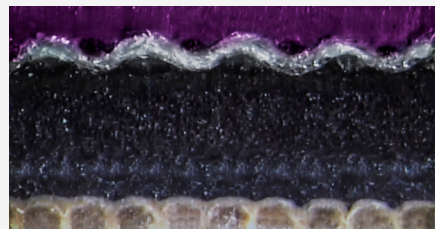

Vulcan UV

✓ The product at a glance

INK COMPATIBILITY	UV
PRINTING SURFACE COLOUR	Purple
THICKNESS (mm)	1,96
AVERAGE LOAD VALUE N/cm² @ 0,23 mm Indentation	250
SURFACE ROUGHNESS (Ra micron)	0,8
ELONGATION (%)	<0,9
TENSILE STRENGTHS (N/mm)	>60
WATER & SOLVENT PROTECTION	No
ADDITIONAL INFORMATION	
APPLICATIONS	The special carcass construction combined with the EPDM top face provides a long life time and less downtime time due to blanket changes

**FOR ANY FURTHER DETAILS AND FOR A QUOTATION
PLEASE REFER TO YOUR SALES MANAGER
OR EMAIL US AT: printingsm@trelleborg.com**