



vulcan[®] Metal Times


Key performance

- Suitable for all newspaper presses
- Better reproduction and print quality
- Faster reboundability for high performance and longer runs
- Improved smash resistance
- Optimized ink water transfer
- Field validated by leading newspaper printers

MAIN APPLICATION

Newspaper

Vulcan Metal Times is available in 2-ply.

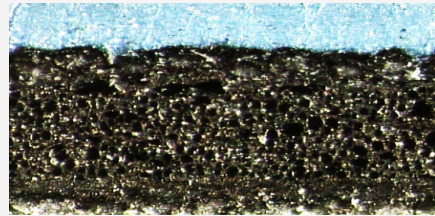

Vulcan Metal Times

✓ The product at a glance

INK COMPATIBILITY	Hybrid
THICKNESS (mm)	According to manufacturer drawing
PRINTING SURFACE COLOUR	Blue
AVERAGE LOAD VALUE N/cm² @ 0,23 mm Indentation	250
SURFACE ROUGHNESS (Ra micron)	1,2
METAL BASE	Stainless steel 0,2 mm
COMPRESSIBLE LAYER	Microspheres closed cells
PAPER FEEDING	Neutral / Slightly positive
ADDITIONAL INFORMATION	
APPLICATIONS	Suitable for all kind of newspaper presses

**FOR ANY FURTHER DETAILS AND FOR A QUOTATION
PLEASE REFER TO YOUR SALES MANAGER
OR EMAIL US AT: printingsm@trelleborg.com**