



vulcan[®] Super UV


Key performance

- Ideal for packaging multi-color solid printing, UV inks
- Excellent half tone reproduction and ink transfer coverage
- High edge marking resistance
- Increased blanket lifetime

MAIN APPLICATION

Packaging, Metal Decorating

Vulcan Super UV is available in 3 ply, 1,96 mm thickness.

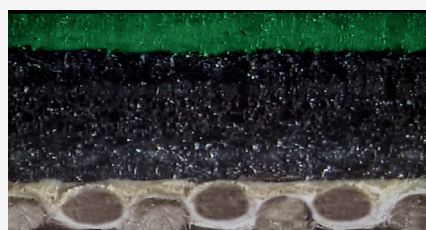

Vulcan Super UV

✓ The product at a glance

INK COMPATIBILITY	UV
PRINTING SURFACE COLOUR	Green
THICKNESS (mm)	1,96
AVERAGE LOAD VALUE N/cm² @ 0,23 mm Indentation	350
SURFACE ROUGHNESS (Ra micron)	0,8
ELONGATION (%)	<0,9
TENSILE STRENGTHS (N/mm)	>60
WATER & SOLVENT PROTECTION	No
ADDITIONAL INFORMATION	
APPLICATIONS	Specifically designed for metal decorating applications

**FOR ANY FURTHER DETAILS AND FOR A QUOTATION
PLEASE REFER TO YOUR SALES MANAGER
OR EMAIL US AT: printingsm@trelleborg.com**