



Printec 835


Key performance

- Ideal for packaging printing and metal decorating, 4-color presses, UV inks
- Excellent half tone reproduction and ink transfer
- High edge marking resistance
- Increased blanket lifetime

MAIN APPLICATION

Packaging,
Metal Decorating UV

Printec 835 is available in 3 ply, 1,96 mm thickness.

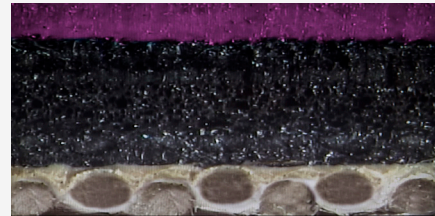

Printec 835

✓ The product at a glance

INK COMPATIBILITY	UV
PRINTING SURFACE COLOUR	Purple
THICKNESS (mm)	1,96
AVERAGE LOAD VALUE N/cm² @ 0,23 mm Indentation	400
SURFACE ROUGHNESS (Ra micron)	0,8
WATER & SOLVENT PROTECTION	No
ADDITIONAL INFORMATION	
DESIGN	Specifically designed for metal decorating applications

**FOR ANY FURTHER DETAILS AND FOR A QUOTATION
PLEASE REFER TO YOUR SALES MANAGER
OR EMAIL US AT: printingsm@trelleborg.com**