




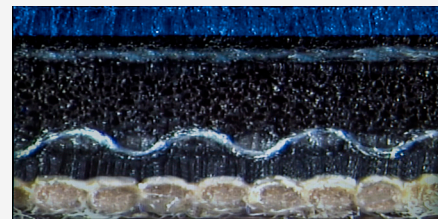
Key performance

- Quick rebound at high speeds
- Excellent print quality and improved blanket durability
- Very good edge marking resistance
- High swelling resistance
- Ideal for large size presses

MAIN APPLICATION

Coldset

Printec 74 is available in 3-ply, 1.96 mm thickness.

Printec 74

✓ The product at a glance

>67

INK COMPATIBILITY	Hybrid
PRINTING SURFACE COLOUR	Blue
THICKNESS (mm)	1.96
AVERAGE LOAD VALUE N/cm² @ 0,23 mm Indentation	250
SURFACE ROUGHNESS (Ra micron)	1,0
FEED FEATURES	Positive
WATER & SOLVENT PROTECTION	Yes
TENSILE STRENGTH (N/MM)	>67
ELONGATION (%)	<0,9
ADDITIONAL INFORMATION	
APPLICATIONS	Dynatech

**FOR ANY FURTHER DETAILS AND FOR A QUOTATION
PLEASE REFER TO YOUR SALES MANAGER
OR EMAIL US AT: printingsm@trelleborg.com**