




Key performance

- Quick rebound at high speeds
- Excellent print quality and improved blanket durability
- Very good edge marking resistance
- High swelling resistance
- Ideal for large size presses

MAIN APPLICATION

Commercial Web Heatset

Printec 73 is available in 3-ply, 1,71 mm thickness.

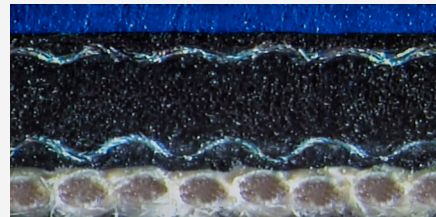

Printec 73



The product at a glance

INK COMPATIBILITY	Hybrid
PRINTING SURFACE COLOUR	Blue
THICKNESS (mm)	1,71
AVERAGE LOAD VALUE N/cm2 @ 0,23 mm Indentation	240
SURFACE ROUGHNESS (Ra micron)	0,8
FEED FEATURES	Slightly positive
WATER & SOLVENT PROTECTION	Yes
TENSILE STRENGTH (N/MM)	>59
ELONGATION (%)	<0,9
ADDITIONAL INFORMATION	
PRESS FORMAT	Suitable for large size presses

**FOR ANY FURTHER DETAILS AND FOR A QUOTATION
PLEASE REFER TO YOUR SALES MANAGER
OR EMAIL US AT: printingsm@trelleborg.com**