



Rollin[®] Resil




Key performance

- Sticky back blanket
- High print quality
- High edge marking resistance
- Increased blanket lifetime
- Suitable for labels and envelopes printing
- Adhesive: clean and easy removal from the cylinder

MAIN APPLICATION

Business Forms, Labels

**Rollin Resil is available in 2 ply,
0,95 - 1,05 mm thickness**

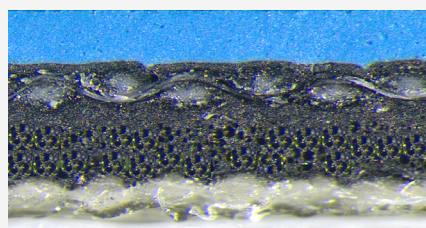

Rollin Resil

✓ The product at a glance

| | |
|--|-------------|
| INK COMPATIBILITY | Hybrid |
| PRINTING SURFACE COLOUR | Blue |
| THICKNESS (mm) | 0,95 - 1,05 |
| AVERAGE LOAD VALUE N/cm² @ 0,23 mm Indentation | 300 |
| SURFACE ROUGHNESS (Ra micron) | 0,8 |
| ELONGATION (%) | <0,7% |
| TENSILE STRENGTH (N/mm) | >55 |

**FOR ANY FURTHER DETAILS AND FOR A QUOTATION
PLEASE REFER TO YOUR SALES MANAGER
OR EMAIL US AT: printingsm@trelleborg.com**