

Rollin[®] RC Series


Key performance

- Specifically designed for strippable and varnishing applications
- Unique Blue Strip Zone
- Blue colored compressible layer offers clean reliable cut outs
- Fine Buff Coating surface for smooth varnish laydown
- Excellent coating transfer and high resistance to ink pick up
- Suitable for flood, spot, knock out coating applications

MAIN APPLICATION

Coating

Rollin RC series is available in .067" - .077" thickness

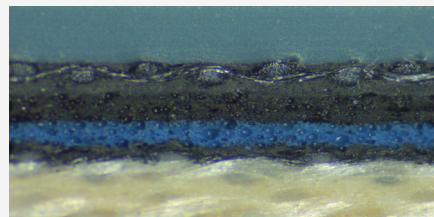

Rollin RC Series

✓ The product at a glance

TYPE OF VARNISH	Conventional & some UV
PRINTING SURFACE COLOUR	Blue Gray
SURFACE	Rubber
THICKNESS (inches)	.067" - .077" +/- .001"
CARRIER	Fabric
CUTTING DEPTH (Inches)	.034" - .037"
AVERAGE LOAD VALUE N/cm² @ 0,23 mm Indentation	250
SURFACE ROUGHNESS (Ra micron)	0,55
ELONGATION (%)	<0,9
TENSILE STRENGTHS (N/mm)	>59

**FOR ANY FURTHER DETAILS AND FOR A QUOTATION
PLEASE REFER TO YOUR SALES MANAGER
OR EMAIL US AT: printingsm@trelleborg.com**