



Rollin[®] Avenir




Key performance

- Quick rebound at high speeds
- Excellent print quality and improved blanket durability
- Very good edge marking resistance
- High swelling resistance
- Optimum gauge control
- Ideal for large size presses

MAIN APPLICATION

Heatset

Rollin Avenir is available in 3-ply, 1,71 mm thickness

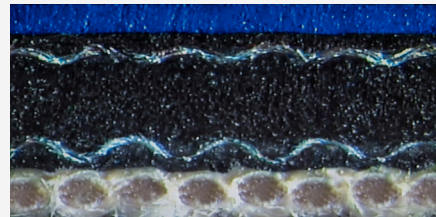

Rollin Avenir



The product at a glance

INK COMPATIBILITY	Hybrid
PRINTING SURFACE COLOUR	Blue
THICKNESS (mm)	1,71
AVERAGE LOAD VALUE N/cm² @ 0,23 mm Indentation	240
SURFACE ROUGHNESS (Ra micron)	0,8
FEED FEATURES	Slightly positive
ELONGATION (%)	<0,9
TENSILE STRENGTH (N/MM)	>59
WATER & SOLVENT PROTECTION	Yes

**FOR ANY FURTHER DETAILS AND FOR A QUOTATION
PLEASE REFER TO YOUR SALES MANAGER
OR EMAIL US AT: printingsm@trelleborg.com**