



Rollin[®] Folder




Key performance

- Ideal for newspaper high speed presses
- Designed with **Feed-0 Technology**:
 - Optimum paper feed tension
 - Reduced risks of paper breaks
 - Easier control of colour register during the start-up
 - Improved paper wastage control

MAIN APPLICATION

Newspaper Coldset

Rollin Folder is available in 4-ply, 1,96 mm thickness

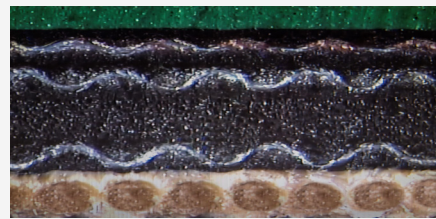

Rollin Folder

✓ The product at a glance

INK COMPATIBILITY	Hybrid
PRINTING SURFACE COLOUR	Green
THICKNESS (mm)	1,96
AVERAGE LOAD VALUE N/cm ² @ 0,23 mm Indentation	250
SURFACE ROUGHNESS (Ra micron)	1,0
FEED FEATURES	Neutral
ELONGATION (%)	<0,9
TENSILE STRENGTH (N/mm)	>75
WATER & SOLVENT PROTECTION	Yes
ADDITIONAL INFORMATION	
ADVANCED TECHNOLOGY	Feed-0

**FOR ANY FURTHER DETAILS AND FOR A QUOTATION
PLEASE REFER TO YOUR SALES MANAGER
OR EMAIL US AT: printingsm@trelleborg.com**