

Rollin® Avenir


Key performance

- Excellent ink transfer and print quality
- Durable life
- High swell resistant top layer
- Optimum gauge control
- Hybrid blanket
- Low stretch fabrics

MAIN APPLICATION

Heatset

**Rollin Avenir is available in
3-ply, 1,71 mm thickness**

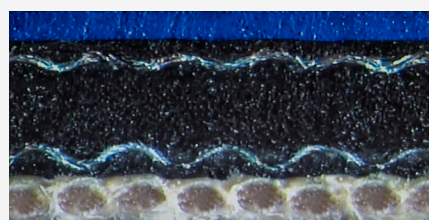

Rollin Avenir

✓ The product at a glance

INK COMPATIBILITY	Hybrid
PRINTING SURFACE COLOUR	Blue
THICKNESS (mm)	1,71
AVERAGE LOAD VALUE N/cm² @ 0,23 mm Indentation	240
SURFACE ROUGHNESS (Ra micron)	0,8
ELONGATION (%)	<0,9
TENSILE STRENGTH (N/mm)	>59
FEED FEATURES	Slightly positive
WATER & SOLVENT PROTECTION	Yes
ADDITIONAL INFORMATION	
PRESS FORMAT	Large size presses

**FOR ANY FURTHER DETAILS AND FOR A QUOTATION
PLEASE REFER TO YOUR SALES MANAGER
OR EMAIL US AT: printingsm@trelleborg.com**