



# Rollin<sup>®</sup> Suntech


## Key performance

- Specifically designed for the latest UV applications (LE/HUV, LED UV)
- Excellent printing quality (solids and half tone reproduction)
- Very good ink release
- Avoid ink back-trapping
- Implements all benefits of the Dynatech System:
  - . Excellent smash and edge marks resistance
  - . Better vibration absorption

## MAIN APPLICATION

Sheeted  
(Commercial & Packaging)

**Rollin Suntech is available in 1.96 mm thickness, 3-ply**

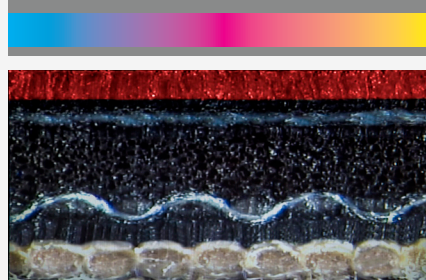

**Rollin Suntech**

## ✓ The product at a glance

<b>INK COMPATIBILITY</b>	UV
<b>PRINTING SURFACE COLOUR</b>	Red
<b>THICKNESS (mm)</b>	1,96
<b>AVERAGE LOAD VALUE N/cm<sup>2</sup> @ 0,23 mm Indentation</b>	250
<b>SURFACE ROUGHNESS (Ra micron)</b>	0,8
<b>ELONGATION (%)</b>	<0,9
<b>TENSILE STRENGTH (N/mm)</b>	>67
<b>ADDITIONAL INFORMATION</b>	
<b>APPLICATIONS</b>	DYNATECH HUV, LED UV

**FOR ANY FURTHER DETAILS AND FOR A QUOTATION  
PLEASE REFER TO YOUR SALES MANAGER  
OR EMAIL US AT: [printingsm@trelleborg.com](mailto:printingsm@trelleborg.com)**