

Rollin[®] Peak


Key performance

- Very good half tone reproduction and overall printing quality
- Proper shock mark absorption
- Excellent paper smash resistance
- Reliable commercial sheetfed performer

MAIN APPLICATION

Commercial Sheetfed,
Packaging

**Rollin Peak is available in 3 ply,
1,96 mm thickness**

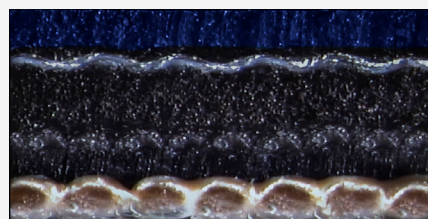

Rollin Peak

✓ The product at a glance

INK COMPATIBILITY	Hybrid
PRINTING SURFACE COLOUR	Blue
THICKNESS (mm)	1,96
AVERAGE LOAD VALUE N/cm² @ 0,23 mm Indentation	245
SURFACE ROUGHNESS (Ra micron)	1,2
ELONGATION (%)	<0,9
TENSILE STRENGTH (N/mm)	>60
ADDITIONAL INFORMATION	
APPLICATIONS	Suitable for alternating printing (UV and conventional)

**FOR ANY FURTHER DETAILS AND FOR A QUOTATION
PLEASE REFER TO YOUR SALES MANAGER
OR EMAIL US AT: printingsm@trelleborg.com**