



Rollin[®] Metal UV


Key performance

- Ideal for UV multi-colour presses
- Excellent half tone reproduction and ink transfer coverage
- Extreme quick release
- High UV chemical resistance

MAIN APPLICATION

Metal decorating,
Packaging, UV

**Rollin Metal UV available in
3 ply, 1,96 mm thickness**

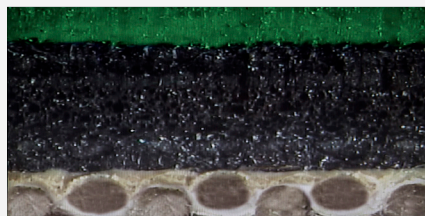

Rollin Metal UV

✓ The product at a glance

INK COMPATIBILITY	UV
PRINTING SURFACE COLOUR	Green
THICKNESS (mm)	1,96
AVERAGE LOAD VALUE N/cm² @ 0,23 mm Indentation	400
SURFACE ROUGHNESS (Ra micron)	0,8
ELONGATION (%)	<0,9
TENSILE STRENGTH (N/mm)	>67
ADDITIONAL INFORMATION	
APPLICATIONS	Packaging and metal decorating

**FOR ANY FURTHER DETAILS AND FOR A QUOTATION
PLEASE REFER TO YOUR SALES MANAGER
OR EMAIL US AT: printingsm@trelleborg.com**