

Rollin® Polycell Plus


Key performance

- Unique blanket design: compressible layer underneath the top compound
- High smash resistance
- Very soft and flexible blanket for easy mounting on press
- Implements all benefits of the Dynatech System:
 - Better vibration absorption
 - Less gears streaking marks
 - Higher paper smash resistance
 - Blanket consistency
 - Excellent reboundability

MAIN APPLICATION

Commercial Sheetfed,
Packaging

**Rollin Polycell is available in
3-ply, 1,96 mm thickness**

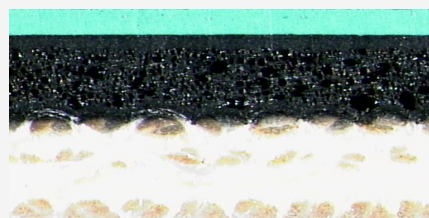

Rollin Polycell Plus



The product at a glance

INK COMPATIBILITY	Hybrid
PRINTING SURFACE COLOUR	Green
THICKNESS (mm)	1,96
AVERAGE LOAD VALUE N/cm ² @ 0,23 mm Indentation	250
SURFACE ROUGHNESS (Ra micron)	0,8
TENSILE STRENGTH (N/mm)	>67
ELONGATION %	<0,9
ADDITIONAL INFORMATION	
ADVANCED TECHNOLOGY	Dynatech System

**FOR ANY FURTHER DETAILS AND FOR A QUOTATION
PLEASE REFER TO YOUR SALES MANAGER
OR EMAIL US AT: printingsm@trelleborg.com**