



# Rollin<sup>®</sup> Metal UV


## Key performance

- Ideal for UV multi-colour presses
- Excellent half tone reproduction and ink transfer coverage
- Extreme quick release
- High UV chemical resistance

## MAIN APPLICATION

Metal decorating,  
Packaging, UV

**Rollin Metal UV available in  
3 ply, 1,96 mm thickness**

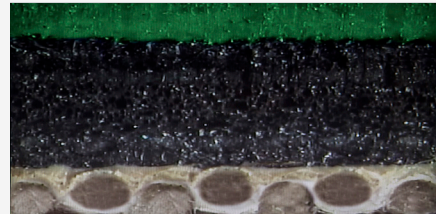

**Rollin Metal UV**

## ✓ The product at a glance

<b>INK COMPATIBILITY</b>	UV
<b>PRINTING SURFACE COLOUR</b>	Green
<b>THICKNESS (mm)</b>	1,96
<b>AVERAGE LOAD VALUE N/cm<sup>2</sup> @ 0,23 mm Indentation</b>	400
<b>SURFACE ROUGHNESS (Ra micron)</b>	0,8
<b>ELONGATION (%)</b>	<0,9
<b>TENSILE STRENGTH (N/MM)</b>	>67
<b>ADDITIONAL INFORMATION</b>	
<b>APPLICATIONS</b>	Packaging and metal decorating

**FOR ANY FURTHER DETAILS AND FOR A QUOTATION  
PLEASE REFER TO YOUR SALES MANAGER  
OR EMAIL US AT: [printingsm@trelleborg.com](mailto:printingsm@trelleborg.com)**