

# Rollin<sup>®</sup>Wish




## Key performance

- Suitable for hybrid printing with both UV and conventional inks
- Increased durability thanks to the top surface strong chemical resistance
- Increased blanket lifetime to maximize the cost per copy
- Sharp half tone for high quality requirements

## MAIN APPLICATION

Commercial Sheetfed,  
Packaging (paper & cardboard)

**Rollin Wish is available in 4 ply,  
1,95 mm thickness.**

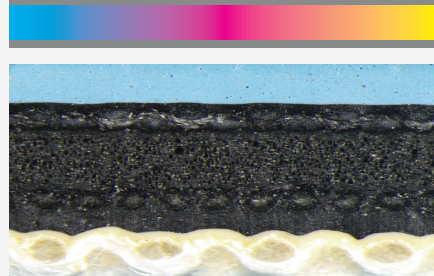

Rollin Wish



## The product at a glance

<b>INK COMPATIBILITY</b>	Hybrid
<b>PRINTING SURFACE COLOUR</b>	Light blue
<b>THICKNESS (mm)</b>	1,95
<b>AVERAGE LOAD VALUE N/cm<sup>2</sup> @ 0,23 mm Indentation</b>	250
<b>SURFACE ROUGHNESS (Ra micron)</b>	0,6
<b>ELONGATION (%)</b>	<0,9
<b>TENSILE STRENGTHS (N/mm)</b>	>60
<b>WATER &amp; SOLVENT PROTECTION</b>	No
<b>ADDITIONAL INFORMATION</b>	
<b>INK TRANSFER</b>	Suitable for printing using both UV and conventional inks

**FOR ANY FURTHER DETAILS AND FOR A QUOTATION  
PLEASE REFER TO YOUR SALES MANAGER  
OR EMAIL US AT: [printingsm@trelleborg.com](mailto:printingsm@trelleborg.com)**